

DN0501




Amplifier pengalih

N605/230VAC/0,8A

Produk tidak tersedia - entri arsip

Produk alternatif: DN1020

Ketika memilih produk dan aksesoris alternatif, perhatikan bahwa data teknis mungkin berbeda!

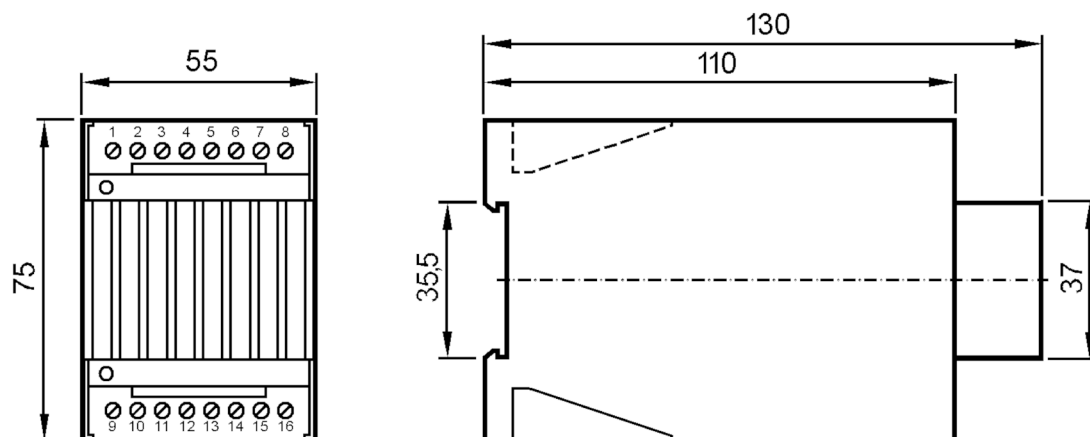

Data kelistrikan

Frekuensi nominal AC	[Hz]	47...63
Tegangan output	[V]	set
Toleransi tegangan output	[%]	5
Arus output maks. pada tegangan output minimal	[A]	0.8
Jumlah sirkuit output		1

Output

Pelindung hubung singkat	ya
Pelindung beban berlebih	ya

Kondisi pengoperasian

Suhu sekitar	[°C]	0...50
Perlindungan		IP 40

Data teknis

Material	plastik
----------	---------

Elemen display/pengoperasian

Display	Tegangan output	2 x LED, hijau
---------	-----------------	----------------

Keterangan

Jumlah paket	1 buah
--------------	--------

DN0501



Amplifier pengalih

N605/230VAC/0,8A

Koneksi listrik

terminal: ...4 mm²

Koneksi

