


Suplai daya mode switch 24 V DC

POWER SUPPLY/24VDC/5A

Produk tidak tersedia - entri arsip

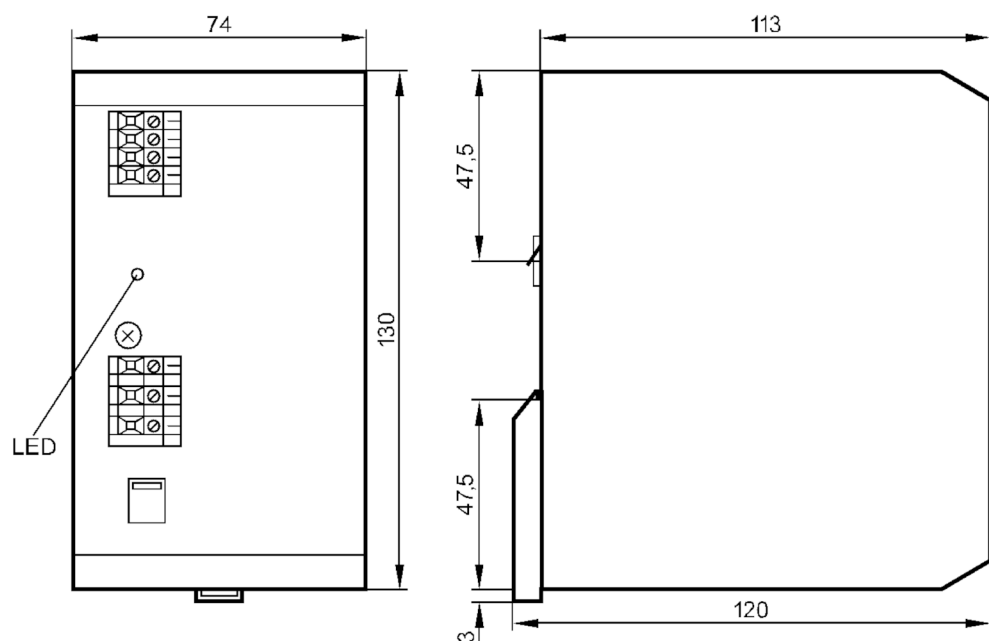

Data kelistrikan

Tegangan nominal AC	[V]	< 230
Frekuensi nominal AC	[Hz]	47...63
Rentang tegangan input AC	[V]	88...132 / 187...264
Kelas perlindungan		I
Waktu penundaan pengaktifan maks.	[ms]	30
Waktu penundaan pengaktifan	[s]	30
Toleransi tegangan output	[%]	2
Arus output maks. pada tegangan output minimal	[A]	5
Jumlah sirkuit output		1
Sisa riak maks.	[%]	1
Sekring	[A]	2; (bawaan)
Derating	[W/K]	1 (60...70 °C)

Output

Pelindung hubung singkat	ya
Pelindung beban berlebih	ya

Kondisi pengoperasian

Suhu sekitar	[°C]	0...60
Perlindungan		IP 20



Suplai daya mode switch 24 V DC

POWER SUPPLY/24VDC/5A

Pengujian/persetujuan		
EME	EN 60950/A2 1993	
	EN 50081-1	
	EN 61000-6-2	
Data teknis		
Material	aluminium	
Elemen display/pengoperasian		
Display	fungsi	LED, hijau
Keterangan		
Jumlah paket	1 buah	
Koneksi listrik		
terminal: ...2.5 mm ²		
Koneksi		

