




Suplai daya mode switch 24 V DC

POWER SUPPLY/24VDC/1A

Produk tidak tersedia - entri arsip

Produk alternatif: DN1020
Ketika memilih produk dan aksesoris alternatif, perhatikan bahwa data teknis mungkin berbeda!

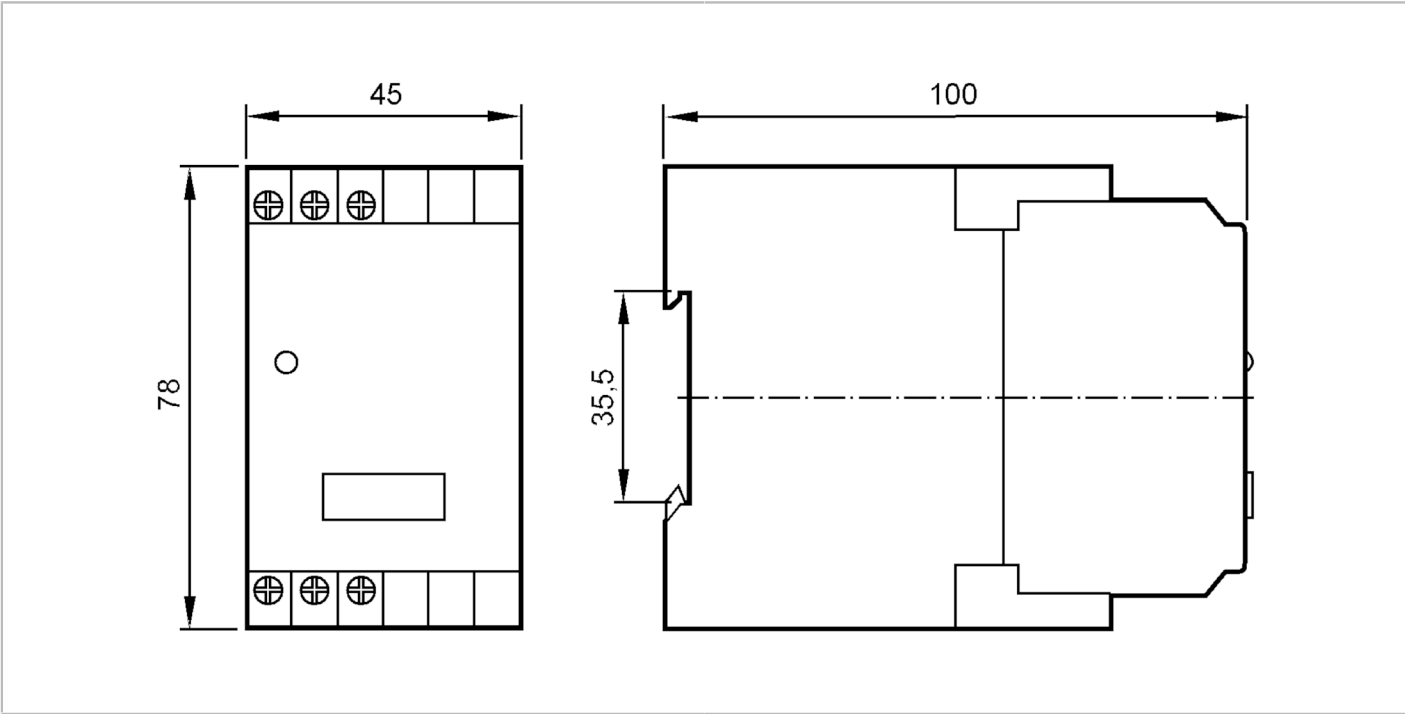

Data kelistrikan		
Tegangan nominal AC	[V]	< 230
Frekuensi nominal AC	[Hz]	47...63
Tegangan input DC	[V]	105...370
Rentang tegangan input AC	[V]	90...260
Kelas perlindungan		I
Toleransi tegangan output	[%]	3
Arus output maks. pada tegangan output minimal	[A]	1
Jumlah sirkuit output		1
Sisa riak maks.	[%]	1.25
Output		
Pelindung hubung singkat		ya
Pelindung beban berlebih		ya
Kondisi pengoperasian		
Suhu sekitar	[°C]	0...55
Perlindungan		IP 20
Pengujian/persetujuan		
EME	EN 50081-1	
	EN 61000-6-2	



Suplai daya mode switch 24 V DC

POWER SUPPLY/24VDC/1A

Data teknis		
Tipe pemasangan	rel; (TH35 (EN 60715))	
Material	plastik	
Elemen display/pengoperasian		
Display	Tegangan output	1 x LED, hijau
Keterangan		
Jumlah paket	1 buah	
Koneksi listrik		
terminal ruang ganda: 2 x ...2.5 mm²		
Koneksi		

