


E3M132



Kabel koneksi dengan soket

POWER SUPPLY CABLE O3M ILLUMINATION 5M

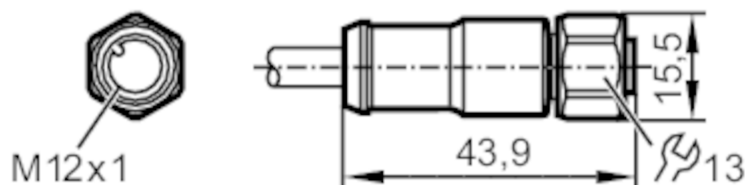

Aplikasi

Fitur khusus

Kontak berlapis emas; Kesesuaian rantai tarik

Data kelistrikan

Tegangan pengoperasian

[V]

< 25 AC / < 60 DC

Kondisi pengoperasian

Suhu sekitar

[°C]

-40...85

Perlindungan

IP 68

Data teknis

Berat

[g]

309.7

Dimensi

[mm]

15.5 x 15.5 x 43.9

Material

PUR

Material bodi detakan

PUR

Material mur

seng tuang

Kesesuaian rantai tarik

ya

Kesesuaian rantai tarik

radius pembengkokan untuk pemasangan tetap

≥ 30 mm

Keterangan

Jumlah paket

1 buah

E3M132



Kabel koneksi dengan soket


POWER SUPPLY CABLE O3M ILLUMINATION 5M

Koneksi listrik

Kabel: 5 m, PUR, hitam, Ø 6 mm; 4 x 0.75 mm²

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang; Kontak: dilapisi emas

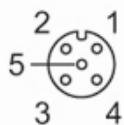

Koneksi

