


E3R100



Kabel koneksi

HFM Y CABLE 2 X S/S/M S/D/M A 2,0M

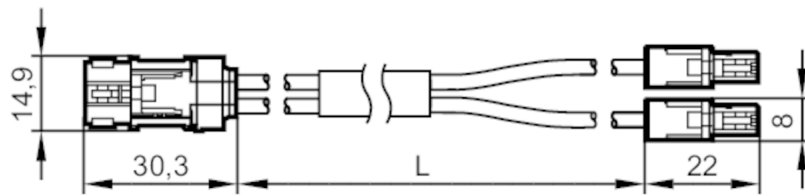

Data kelistrikan

Tegangan pengoperasian [V]	< 50 AC / < 60 DC
Kelas perlindungan	III
Peredam [dB/m]	1.6
Tesistensi internal (Ri) [Ω]	50; (± 3 %)

Kondisi pengoperasian

Suhu sekitar [°C]	-10...60
Suhu sekitar (bergerak) [°C]	-10...60
Perlindungan	IP 54

Data teknis

Berat [g]	91.62
Radius pembengkokan min. [mm]	16.5; (tunggal; 15 x 3,3 mm min. 10 x diameter kabel)
Material	casing: : PBT-GF20

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - Kamera 3D

Konektor: 1 x HFM-Dual, lurus

Koneksi listrik

Kabel: 2 m, hitam, Ø 3.3 mm

Koneksi listrik - Unit Pemrosesan Video

Konektor: 2 x HFM-Single, lurus