

# E10401



## Kabel koneksi dengan soket

ADOAF032MSS0005E03

Produk tidak tersedia - entri arsip



### Data kelistrikan

|                        |     |            |
|------------------------|-----|------------|
| Tegangan pengoperasian | [V] | 10...30 DC |
| Kelas perlindungan     |     | III        |

### Kondisi pengoperasian

|              |      |          |
|--------------|------|----------|
| Suhu sekitar | [°C] | -25...90 |
| Perlindungan |      | IP 67    |

### Data teknis

|                       |      |                          |
|-----------------------|------|--------------------------|
| Dimensi               | [mm] | 17 x 10 x 26             |
| Material              |      | TPU transparan           |
| Material bodi detakan |      | TPU, transparan          |
| Material mur          |      | kuningan, berlapis nikel |

### Elemen display/pengoperasian

|         |                  |                 |
|---------|------------------|-----------------|
| Display | status peralihan | 1 x LED, kuning |
|         | operasi          | 1 x LED, hijau  |

### Keterangan

|              |        |
|--------------|--------|
| Jumlah paket | 1 buah |
|--------------|--------|

# E10401



## Kabel koneksi dengan soket

ADOAF032MSS0005E03

### Koneksi listrik


Kabel: 5 m, PVC, oranye, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Koneksi listrik - soket

Konektor: 1 x M8, bersiku; pengkodean: A; Bodi cetakan: TPU, transparan; Penguncian: kuningan, berlapis nikel



### Koneksi

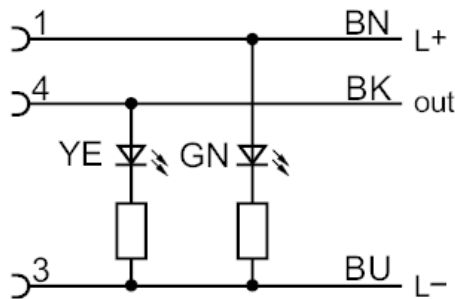

BN =  
BK =  
BU =

Warna core :  
coklat  
hitam  
biru