


# E10411



## Colokan adaptor

ESTGH040MSS00,5E04 (PG9)

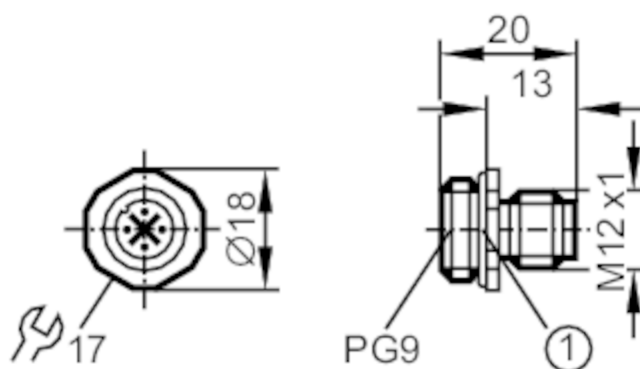

1 O-ring



### Data kelistrikan

|                        |     |               |
|------------------------|-----|---------------|
| Tegangan pengoperasian | [V] | < 250 AC/DC   |
| Total beban arus maks. | [A] | 4; (...40 °C) |

### Kondisi pengoperasian

|              |      |          |
|--------------|------|----------|
| Suhu sekitar | [°C] | -25...85 |
| Perlindungan |      | IP 67    |

### Data teknis

|                       |      |                            |
|-----------------------|------|----------------------------|
| Berat                 | [g]  | 17.1                       |
| Dimensi               | [mm] | 18 x 18 x 20               |
| Ulir pemasangan       |      | PG 9                       |
| Material              |      | seng tuang berlapis nikel  |
| Material bodi detakan |      | seng tuang, berlapis nikel |

### Keterangan

|              |        |
|--------------|--------|
| Jumlah paket | 1 buah |
|--------------|--------|



## Colokan adaptor

ESTGH040MSS00,5E04 (PG9)

### Koneksi listrik

Kabel: 0.5 m, PVC; 4 x 0.25 mm<sup>2</sup>

### Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: seng tuang, berlapis nikel



### Koneksi

|   |    |
|---|----|
| 1 | BN |
| 2 | WH |
| 3 | BU |
| 4 | BK |

BK =  
BN =  
BU =  
WH =

Warna core :  
hitam  
coklat  
biru  
putih