

E10416



Kabel koneksi dengan soket

ADOAH040MSS0005A03

Produk tidak tersedia - entri arsip



Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC / < 300 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	27 x 15 x 39
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 5 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)		
Koneksi listrik - soket		

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm






Kabel koneksi dengan soket

ADOAH040MSS0005A03

Koneksi

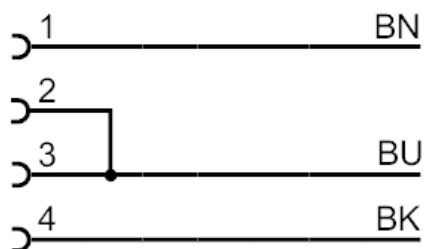

BN =	Warna core :	coklat
BK =		hitam
BU =		biru