


E10437



Splitter Y

ZDO2H040MSS0005H05

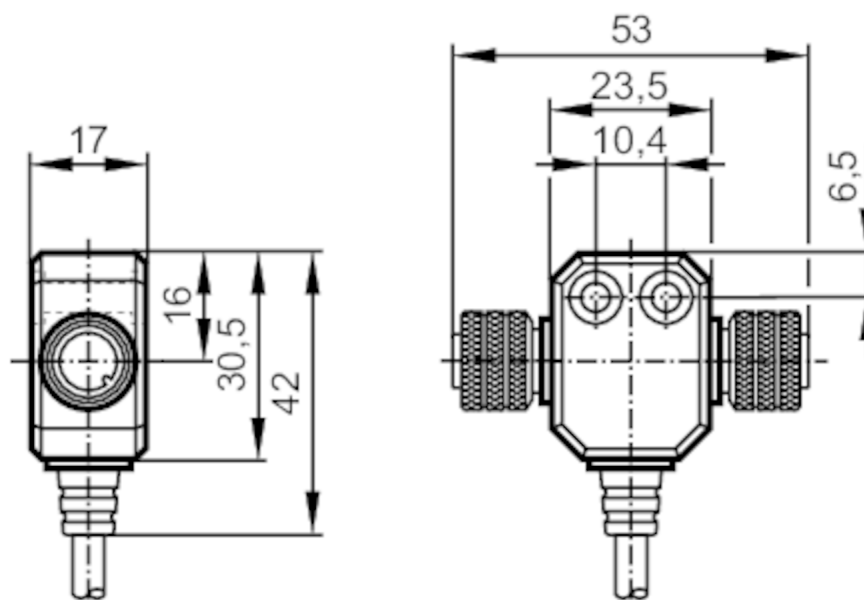

Aplikasi

Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	10...55 DC
Beban arus maks. per modul/slot	[A]	4
Total beban arus maks.	[A]	4

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67

Data teknis

Berat	[g]	160.7
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Jumlah port kotak splitter		2
Tipe konektor		M12

Keterangan

Jumlah paket		1 buah
--------------	--	--------



Splitter Y

 
ZDO2H040MSS0005H05

Koneksi listrik

Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 2 x M12; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.5 Nm



Koneksi

BN	1 (1...2)	C
BU	3 (1...2)	C
BK	4 (1)	C
WH	4 (2)	C

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
WH =	putih