





Soket berkabel

SDOGM120MSSFKPG

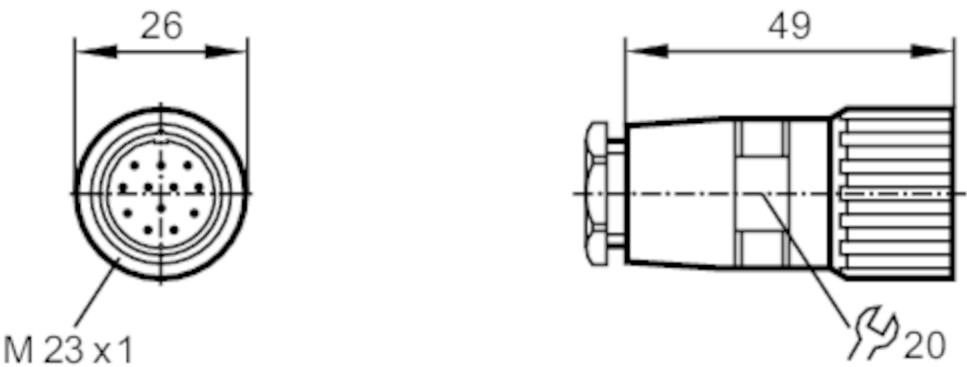

Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Total beban arus maks.	[A]	7.5
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 65
Data teknis		
Berat	[g]	77
Dimensi	[mm]	26 x 26 x 49
Material		kuningan berlapis nikel
Material bodi detakan		kuningan, berlapis nikel
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
penyolderan: ...1 mm²; Selubung kabel: Ø 10...14 mm		
Koneksi listrik - soket		
Konektor: 1 x M23, lurus; Bodi cetakan: kuningan, berlapis nikel; Penguncian: kuningan, berlapis nikel		

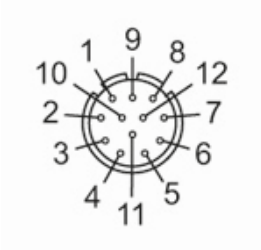

E10448



Soket berkabel

SDOGM120MSSFKPG

Koneksi

