
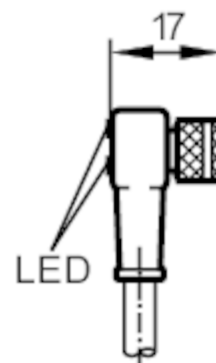


Kabel koneksi dengan soket

ADOAF032MSS0020A03

Produk tidak tersedia - entri arsip

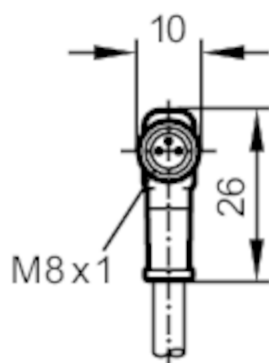

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
Kelas perlindungan		III

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Dimensi	[mm]	17 x 10 x 26
Material		TPU transparan
Material bodi detakan		TPU, transparan
Material mur		kuningan, berlapis nikel

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

E10453



Kabel koneksi dengan soket

ADOAF032MSS0020A03

Koneksi listrik


Kabel: 20 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M8, bersiku; pengkodean: A; Bodi cetakan: TPU, transparan; Penguncian: kuningan, berlapis nikel



Koneksi

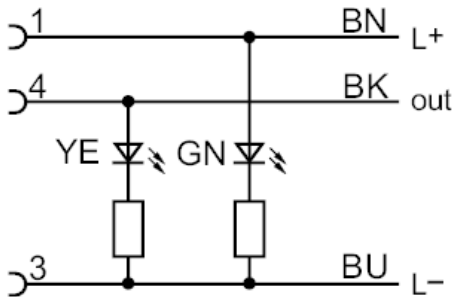

BN = Warna core :
BK = coklat
BU = hitam
 biru