


Kabel koneksi

VDOGH042MSS00,6A04STGH040MSS

Produk tidak tersedia - entri arsip

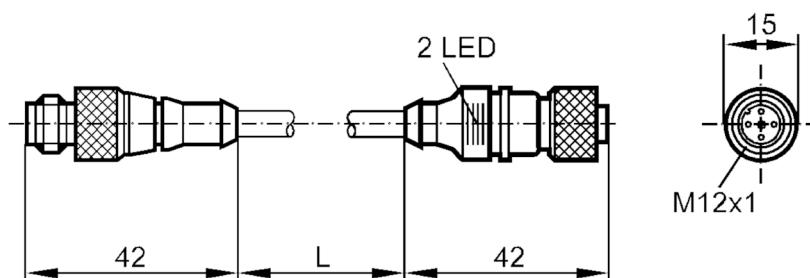

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
--------------	------	----------

Perlindungan	IP 67
--------------	-------

Data teknis

Material	TPU
Material bodi detakan	TPU
Material mur	kuningan, berlapis nikel

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm



E10458




Kabel koneksi

VDOGH042MSS00,6A04STGH040MSS

Koneksi listrik

Kabel: 0.6 m, PUR / PVC; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Koneksi

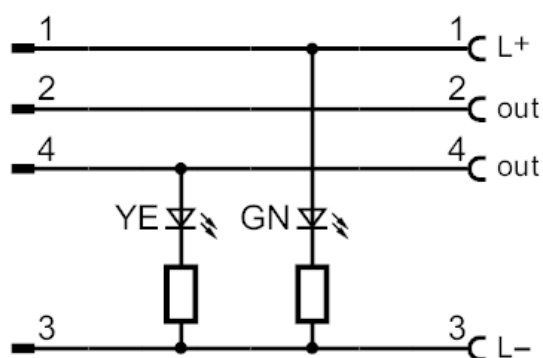

BK =
BN =
BU =
WH =

Warna core :
hitam
coklat
biru
putih

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

