

E10463



Kabel koneksi

VDOGH040MSS00,6A04STGH040MSS

Produk tidak tersedia - entri arsip



Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
Perlindungan		IP 67

Data teknis


Dimensi	[mm]	15 x 15 x 42
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

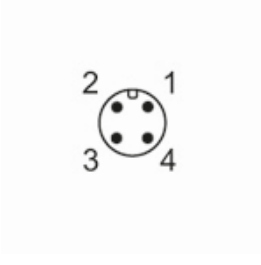



Kabel koneksi

VDOGH040MSS00,6A04STGH040MSS

Koneksi listrik

Kabel: 0.6 m, PUR / PVC; 4 x 0.25 mm²

Koneksi



Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

