


E10465



Kabel koneksi

VDOGH040MSS01,5A04STGH040MSS

Produk tidak tersedia - entri arsip

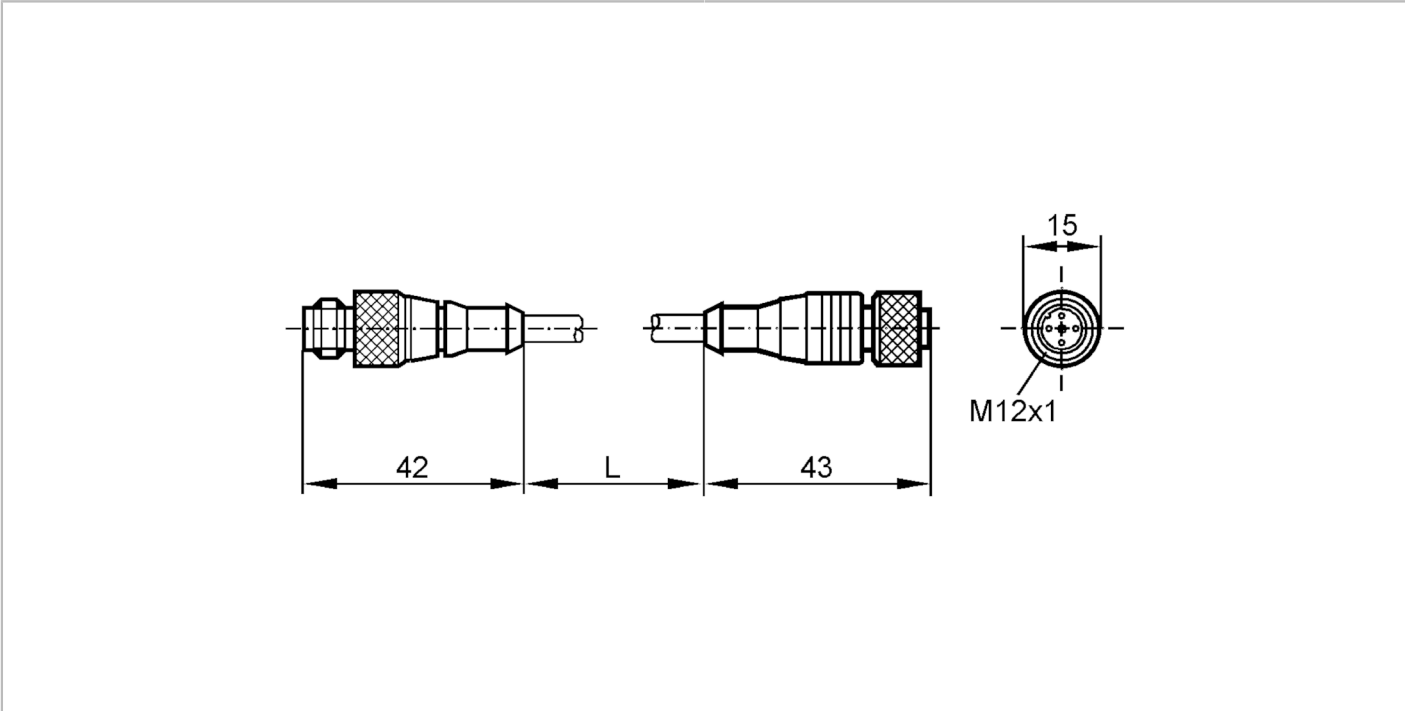

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
Perlindungan		IP 67

Data teknis


Dimensi	[mm]	15 x 15 x 42
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel

Keterangan

Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

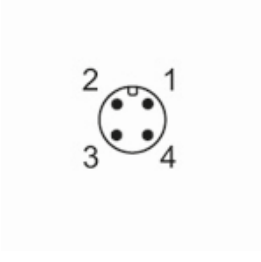




Kabel koneksi

VDOGH040MSS01,5A04STGH040MSS

Koneksi listrik

Kabel: 1.5 m, PUR / PVC, oranye; 4 x 0.25 mm² (128 x Ø 0.1 mm)

Koneksi

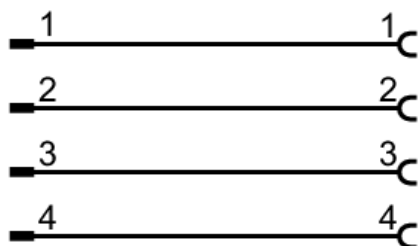

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

