



Colokan adaptor


ESTGH020MSS0,05E02 (PG13,5)

Produk tidak tersedia - entri arsip

1 O-ring

Data kelistrikan		
Tegangan pengoperasian	[V]	< 55 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...85
Perlindungan		IP 67
Data teknis		
Ulir pemasangan		PG 13.5
Material		kuningan berlapis nikel
Material bodi detakan		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 0.055 m, PVC; 2 x 0.25 mm²		
Koneksi listrik - colokan		

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: kuningan, berlapis nikel

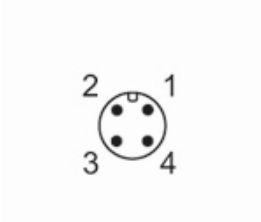




Colokan adaptor

ESTGH020MSS0,05E02 (PG13,5)

 Koneksi



BN = Warna core :
BU = coklat
 biru