


E10474



Splitter Y

ZDOAH040MSS0,07A02DOGH040MSS

Produk tidak tersedia - entri arsip

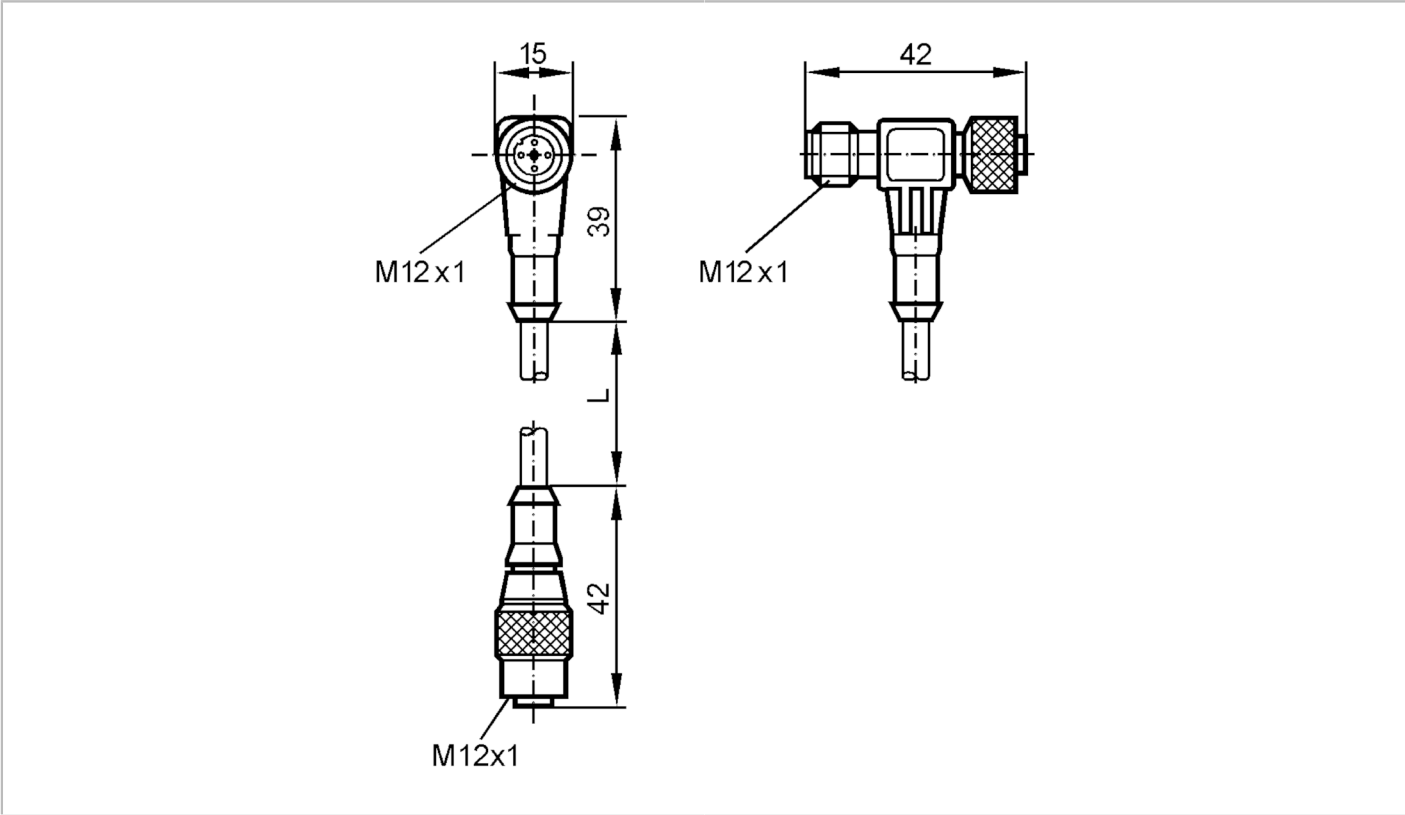

Data kelistrikan		
Tegangan pengoperasian	[V]	10...60 AC/DC
Beban arus maks. per modul/slot	[A]	4
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Jumlah port kotak splitter		2
Keterangan		
Jumlah paket		1 buah

Splitter Y

ZDOAH040MSS0,07A02DOGH040MSS

Koneksi listrik


Kabel: 0.77 m, PUR / PVC, hitam, Ø 5 mm; 2 x 0.34 mm² (32 x Ø 0.1 mm)

Koneksi listrik - colokan

Konektor: 2 x M12; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm



Koneksi

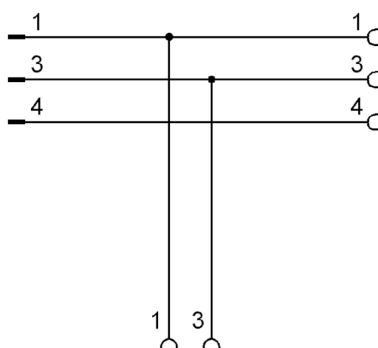

Koneksi listrik - soket

Konektor: 2 x M12; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

