


Kabel koneksi dengan soket

ADOAH042MSS0010F03

Produk tidak tersedia - entri arsip

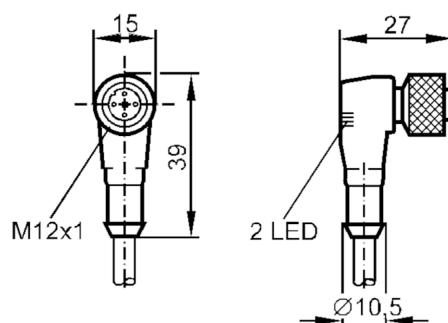

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
--------------	------	----------

Perlindungan	IP 67
--------------	-------

Data teknis

Dimensi	[mm]	27 x 15 x 39
---------	------	--------------

Material	TPU transparan
----------	----------------

Material bodi detakan	TPU, transparan
-----------------------	-----------------

Material mur	kuningan, anti-percikan
--------------	-------------------------

Keterangan

Jumlah paket	1 buah
--------------	--------

E10491



Kabel koneksi dengan soket

ADOAH042MSS0010F03

Koneksi listrik


Kabel: 10 m, PVC, oranye, Ø 5 mm; terkoneksi silang; 3 x 0.34 mm² (19 x Ø 0.15 mm)

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU, transparan; Penguncian: kuningan, anti-percikan



Koneksi

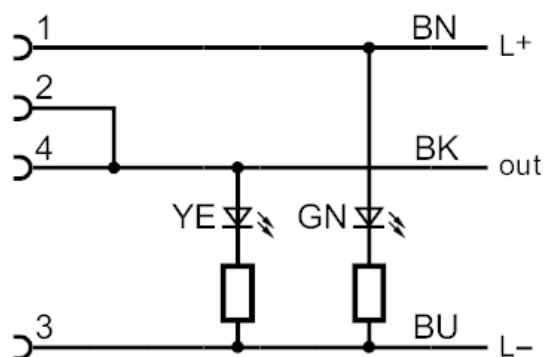

BN =
BK =
BU =

Warna core :
coklat
hitam
biru