




Kabel koneksi dengan soket

ADOGH040MSS0005F03

Produk tidak tersedia - entri arsip

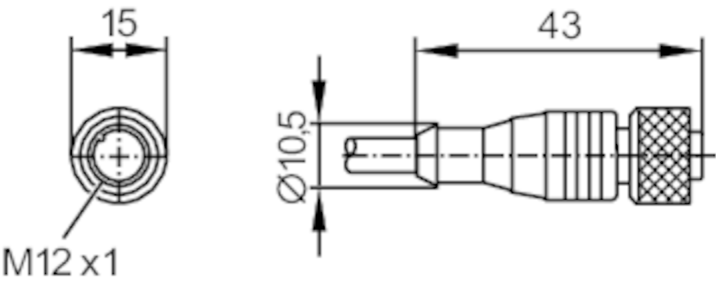

Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC / < 300 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	15 x 15 x 43
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, anti-percikan
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 5 m, PVC, oranye, Ø 5 mm; terkoneksi silang; 3 x 0.34 mm²		
Koneksi listrik - soket		

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, anti-percikan






Kabel koneksi dengan soket

ADOGH040MSS0005F03

Koneksi

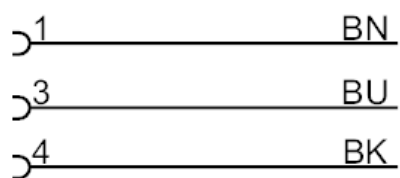

BN =	Warna core :	coklat
BK =		hitam
BU =		biru