


E10548



Kabel koneksi

VDOGG030--S0001A03STGH030MSS

Produk tidak tersedia - entri arsip

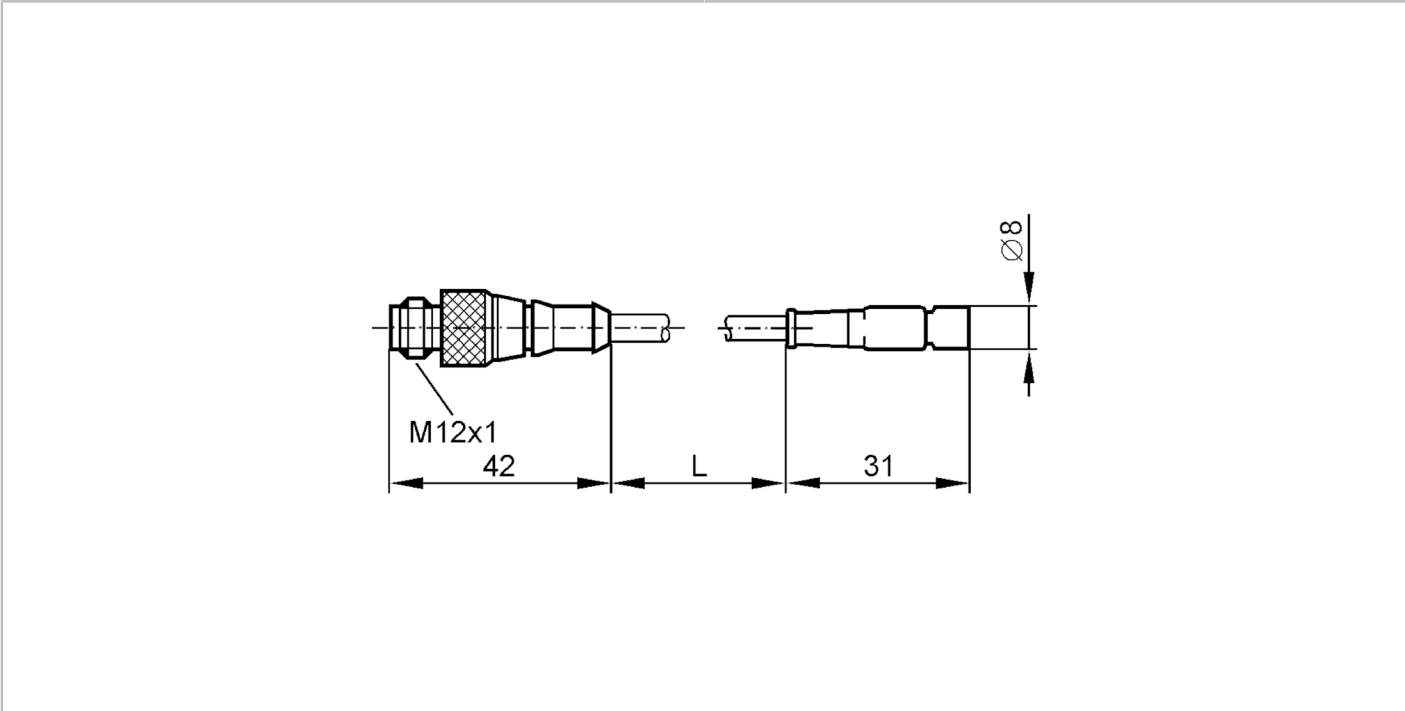

Data kelistrikan		
Tegangan pengoperasian	[V]	< 60 AC / < 75 DC
Kelas perlindungan		III

Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis		
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel

Keterangan		
Jumlah paket		1 buah

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel



E10548




Kabel koneksi

VDOGG030--S0001A03STGH030MSS

Koneksi listrik

Kabel: 1 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi

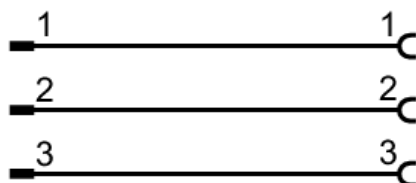

Koneksi listrik - soket

Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

