



Kabel koneksi


VDOGG030--S00,3A03STGH030MSS

Produk tidak tersedia - entri arsip



| Data kelistrikan          |      |                          |
|---------------------------|------|--------------------------|
| Tegangan pengoperasian    | [V]  | < 60 AC / < 75 DC        |
| Kelas perlindungan        |      | III                      |
| Kondisi pengoperasian     |      |                          |
| Suhu sekitar              | [°C] | -25...90                 |
| Perlindungan              |      | IP 67                    |
| Data teknis               |      |                          |
| Material                  |      | TPU                      |
| Material bodi detakan     |      | TPU                      |
| Material mur              |      | kuningan, berlapis nikel |
| Keterangan                |      |                          |
| Jumlah paket              |      | 1 buah                   |
| Koneksi listrik - colokan |      |                          |

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

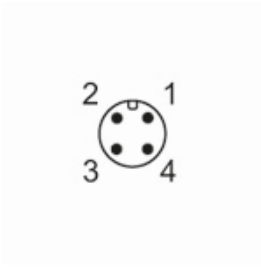



## Kabel koneksi

VDOGG030--S00,3A03STGH030MSS

### Koneksi listrik

Kabel: 0.3 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Koneksi



### Koneksi listrik - soket

Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

