


Kabel koneksi

VDOAG032--S01,5A03STGH030MSS

Produk tidak tersedia - entri arsip

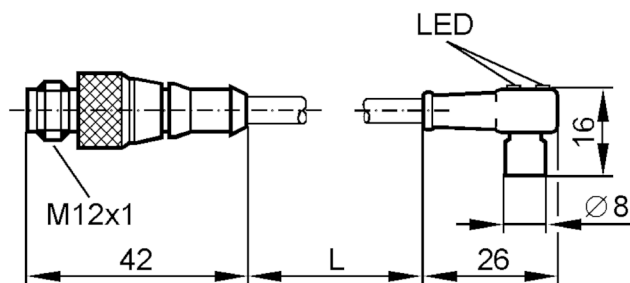

Data kelistrikan

Tegangan pengoperasian [V]	10...30 DC
Kelas perlindungan	III

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar [°C]	-25...90
Perlindungan	IP 67

Data teknis

Material	PUR
Material bodi detakan	PUR
Material mur	kuningan, berlapis nikel

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

Kabel koneksi

VDOAG032--S01,5A03STGH030MSS

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel



Koneksi listrik

Kabel: 1.5 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)


Koneksi



Koneksi listrik - Buchse



Koneksi

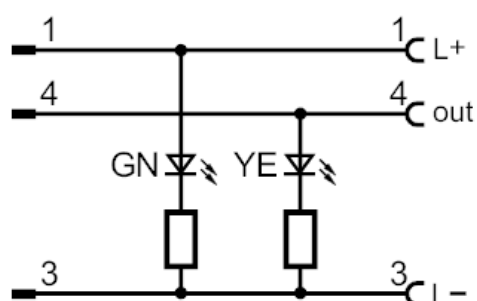

E10554



Kabel koneksi

VDOAG032--S01,5A03STGH030MSS

Koneksi listrik - soket

Konektor: 1 x M8, bersiku; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel