




Kabel koneksi dengan soket

ADOGH040MSS0020E03

Produk tidak tersedia - entri arsip

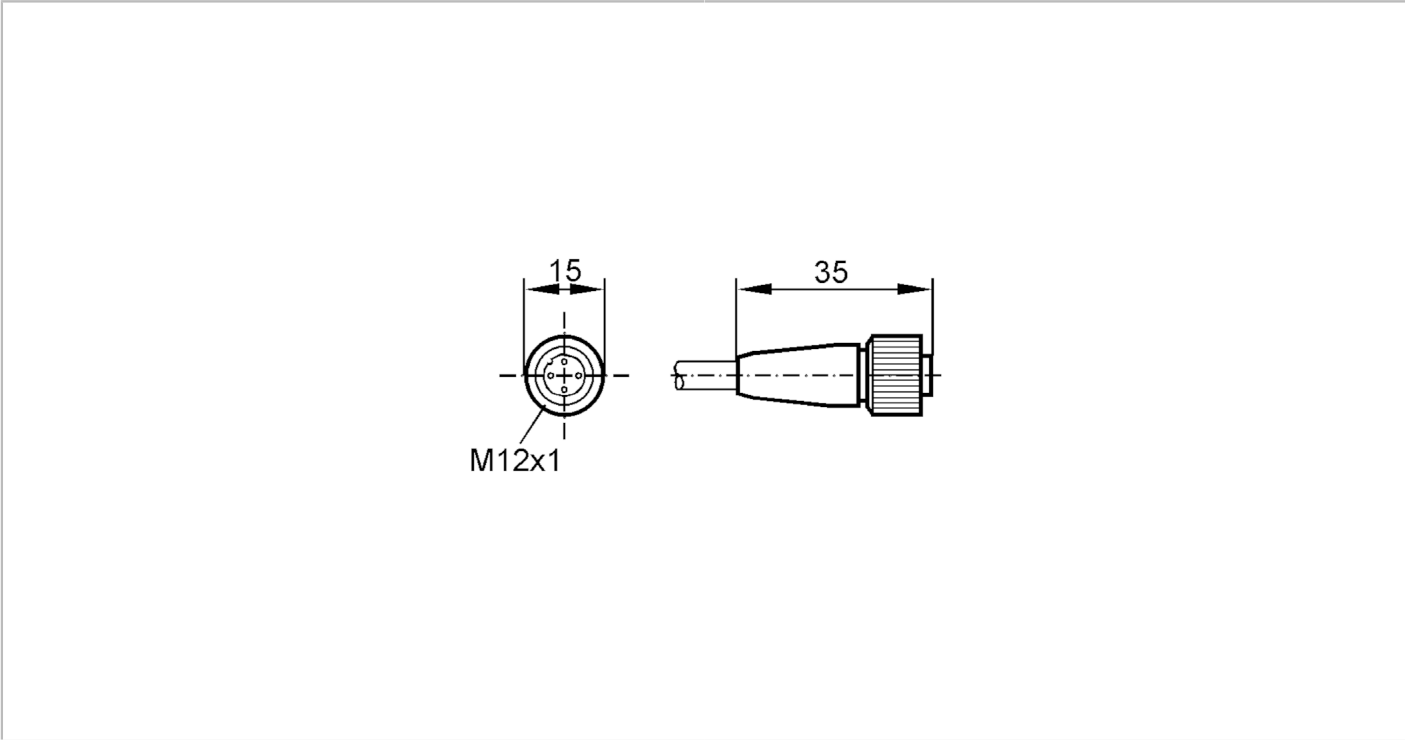

Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC / < 300 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...70
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	15 x 15 x 35
Material		PA 6.6
Material bodi detakan		PA 6.6
Material mur		POM
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 20 m, PVC, kuning, Ø 5.84 mm; 3 x 0.34 mm² / AWG 22		
Koneksi listrik - soket		

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PA 6.6; Penguncian: POM




E10560



Kabel koneksi dengan soket

ADOGH040MSS0020E03

Koneksi

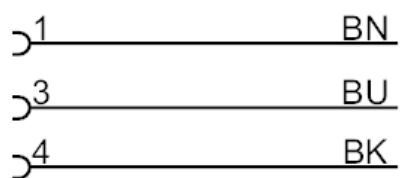

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru