




Adaptor

VSTGH040ALS0000-04STGH040ALS

Produk tidak tersedia - entri arsip

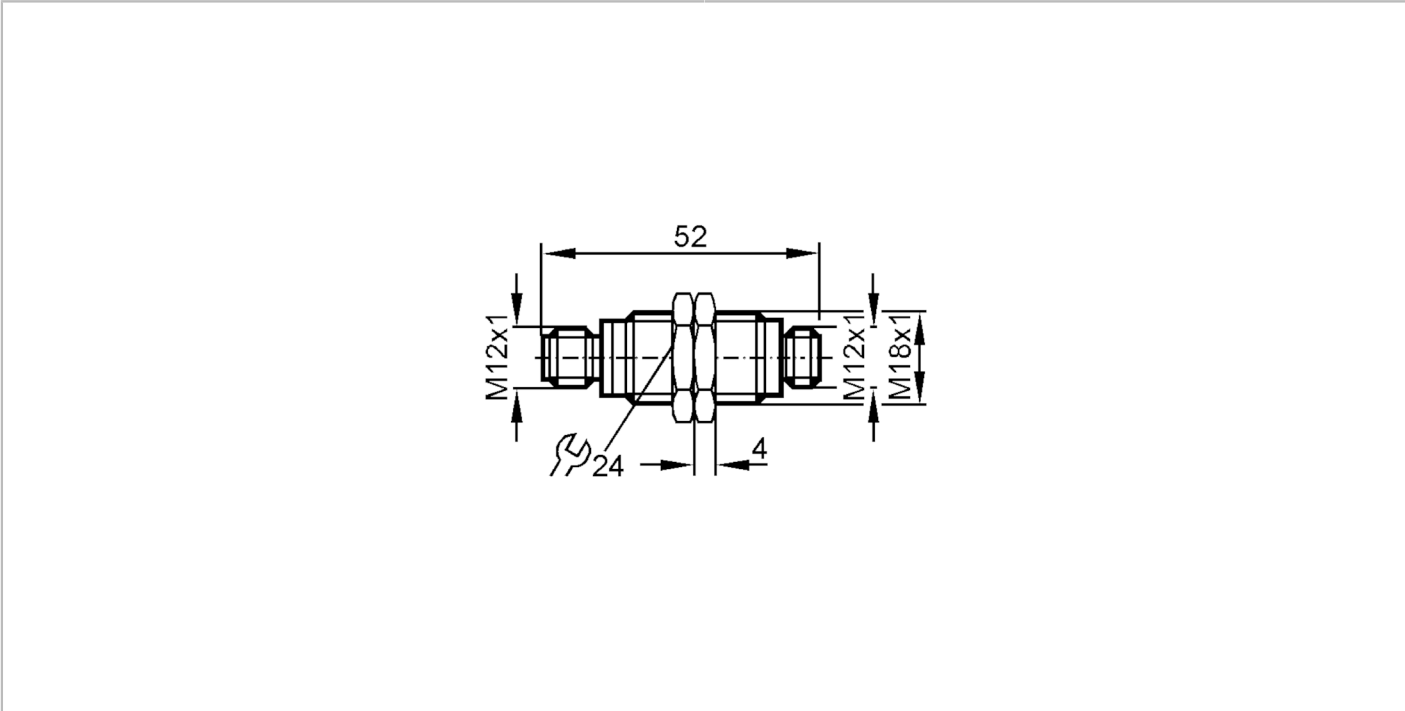

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-20...70
Perlindungan		IP 67

Data teknis


Material	aluminium
Material bodi detakan	aluminium
Material mur	aluminium

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: aluminium; Penguncian: aluminium

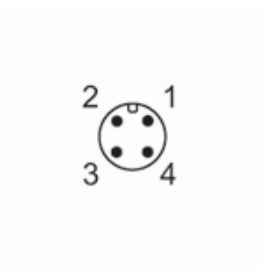




Adaptor

VSTGH040ALS0000-04STGH040ALS

Koneksi

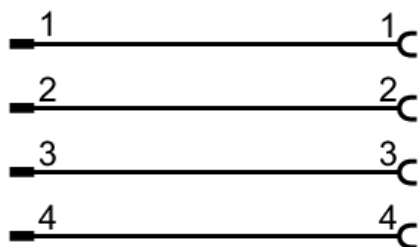

Koneksi listrik - soket

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: aluminium; Penguncian: aluminium

