


Kabel koneksi dengan soket

ADOAH042MSS0002B03

Produk tidak tersedia - entri arsip

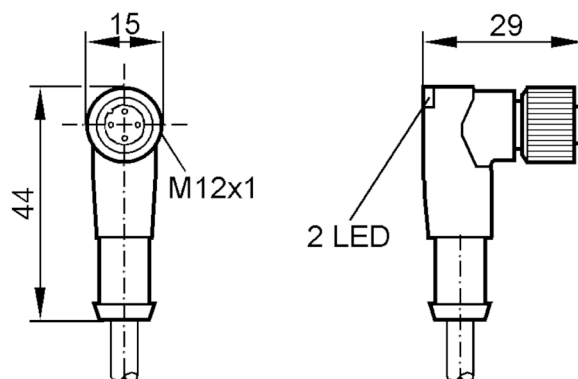

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-20...70
--------------	------	----------

Perlindungan	IP 67
--------------	-------

Data teknis

Dimensi	[mm]	29 x 15 x 44
---------	------	--------------

Material	PA 6.6
----------	--------

Material bodi detakan	PA 6.6
-----------------------	--------

Material mur	aluminium
--------------	-----------

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

E10564



Kabel koneksi dengan soket

ADOAH042MSS0002B03

Koneksi listrik

Kabel: 2 m, PUR, oranye, Ø 4.5 mm; 3 x 0.34 mm²

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PA 6.6; Penguncian: aluminium



Koneksi



BN =	Warna core :
BK =	coklat
BU =	hitam
	biru