


## Kabel koneksi dengan soket

ADOAH042MSS0007E03

Produk tidak tersedia - entri arsip

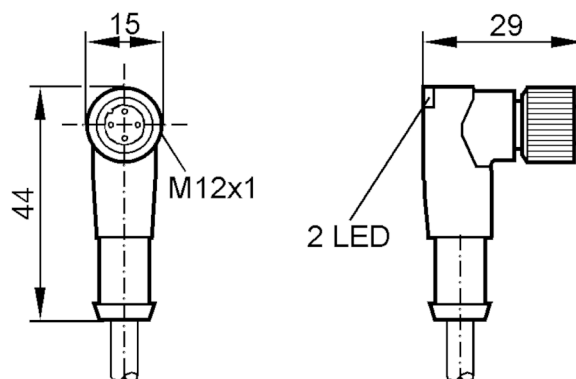

## Data kelistrikan

|                        |     |            |
|------------------------|-----|------------|
| Tegangan pengoperasian | [V] | 10...30 DC |
|------------------------|-----|------------|

## Output

|                    |     |
|--------------------|-----|
| Desain kelistrikan | PNP |
|--------------------|-----|

## Kondisi pengoperasian

|              |      |          |
|--------------|------|----------|
| Suhu sekitar | [°C] | -20...70 |
|--------------|------|----------|

|              |       |
|--------------|-------|
| Perlindungan | IP 67 |
|--------------|-------|

## Data teknis

|         |      |              |
|---------|------|--------------|
| Dimensi | [mm] | 29 x 15 x 44 |
|---------|------|--------------|

|          |        |
|----------|--------|
| Material | PA 6.6 |
|----------|--------|

|                       |        |
|-----------------------|--------|
| Material bodi detakan | PA 6.6 |
|-----------------------|--------|

|              |           |
|--------------|-----------|
| Material mur | aluminium |
|--------------|-----------|

## Elemen display/pengoperasian

|         |                  |                 |
|---------|------------------|-----------------|
| Display | status peralihan | 1 x LED, kuning |
|         | operasi          | 1 x LED, hijau  |

## Keterangan

|              |        |
|--------------|--------|
| Jumlah paket | 1 buah |
|--------------|--------|

# E10565



## Kabel koneksi dengan soket

ADOAH042MSS0007E03

### Koneksi listrik

Kabel: 7 m, PUR, oranye, Ø 4.5 mm; 3 x 0.34 mm<sup>2</sup>

### Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PA 6.6; Penguncian: aluminium



### Koneksi



|      |              |
|------|--------------|
| BN = | Warna core : |
| BK = | coklat       |
| BU = | hitam        |
|      | biru         |