




Kabel koneksi

VDOAH042MSS0002B03STGH040MSS

Produk tidak tersedia - entri arsip

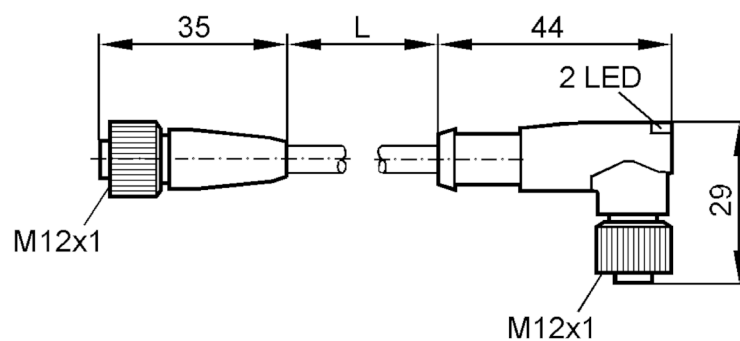

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-20...70
--------------	------	----------

Perlindungan	IP 67
--------------	-------

Data teknis

Material	PA 6.6
----------	--------

Material bodi detakan	PA 6.6
-----------------------	--------

Material mur	aluminium, dianodisasi hitam
--------------	------------------------------

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------



Kabel koneksi

VDOAH042MSS0002B03STGH040MSS

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PA 6.6; Penguncian: aluminium, dianodisasi hitam



Koneksi listrik

Kabel: 2 m, PUR, oranye; terkoneksi silang; 3 x 0.34 mm²

Koneksi



Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PA 6.6; Penguncian: aluminium, dianodisasi hitam

