


E10576



Kabel koneksi dengan soket

ADOAH042MSS0002A03

Produk tidak tersedia - entri arsip

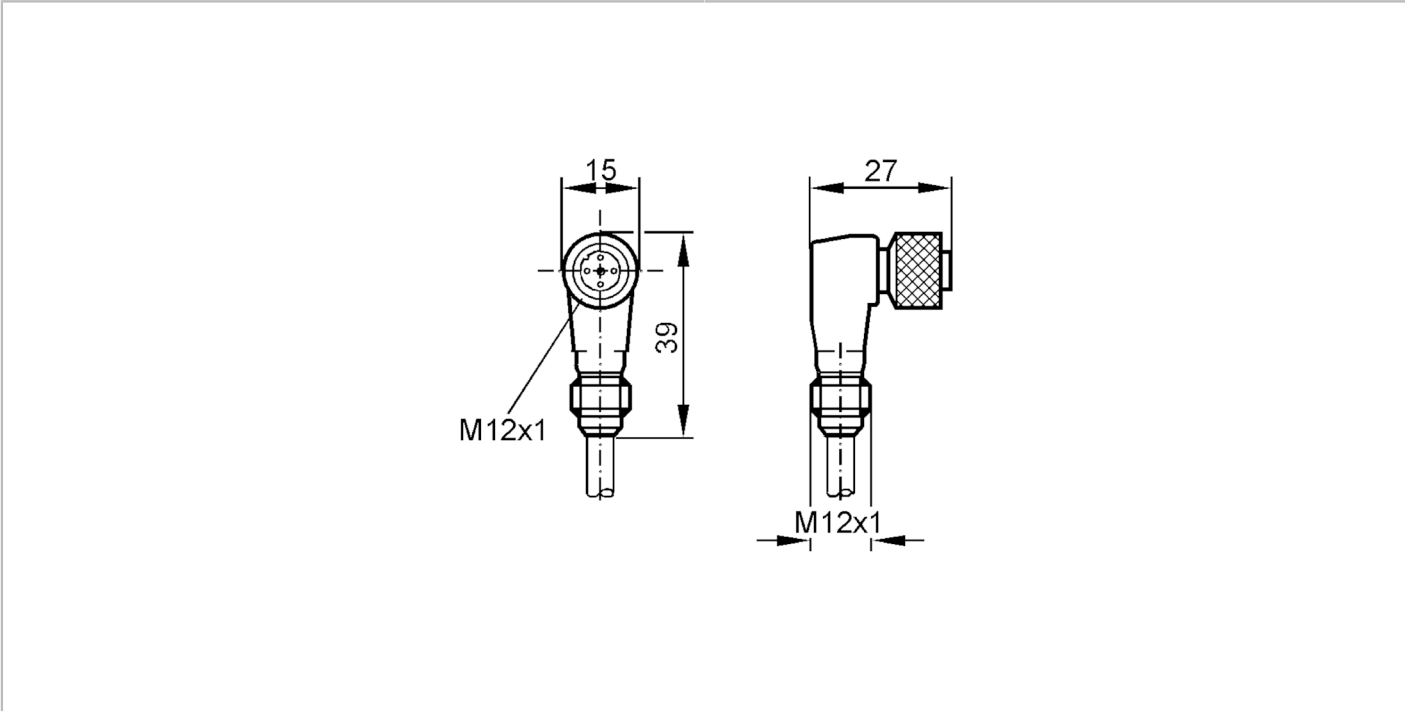

Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Output		
Desain kelistrikan		PNP
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	27 x 15 x 39
Material		TPU transparan
Material bodi detakan		TPU, transparan
Material mur		kuningan, berlapis nikel
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau
Keterangan		
Jumlah paket		1 buah

E10576



Kabel koneksi dengan soket

ADOAH042MSS0002A03

Koneksi listrik


Kabel: 2 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU, transparan; Penguncian: kuningan, berlapis nikel



Koneksi

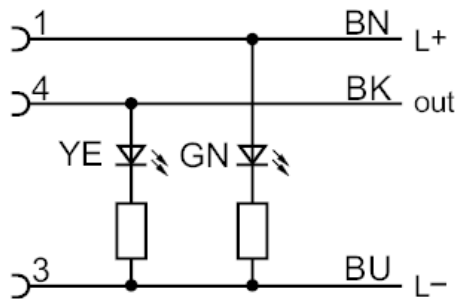

BN =
BK =
BU =

Warna core :
coklat
hitam
biru