


# E10591



## Kabel koneksi dengan soket

ADOAH042VAS07,5E03

Produk tidak tersedia - entri arsip

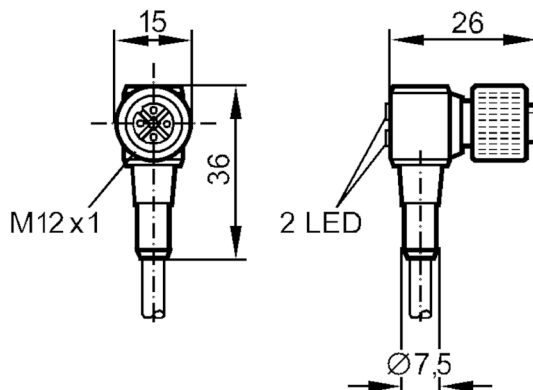

### Data kelistrikan

Tegangan pengoperasian [V] 10...30 DC

### Output

Desain kelistrikan PNP

### Kondisi pengoperasian

Suhu sekitar [°C] -25...90

Perlindungan IP 67

### Data teknis

Material PUR

Material bodi detakan PUR

Material mur baja tahan karat (1.4305/303)

### Keterangan

 
Jumlah paket 1 buah

### Koneksi listrik

Kabel: 7.5 m, PVC, hitam, Ø 4.5 mm; 3 x 0.34 mm²

### Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: baja tahan karat (1.4305/303)



# E10591



## Kabel koneksi dengan soket

ADOAH042VAS07,5E03

### Koneksi



BK =  
BN =  
BU =

Warna core :  
hitam  
coklat  
biru