

Kabel koneksi dengan soket

ADOAH042VAS0025E03

Produk tidak tersedia - entri arsip



Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
--------------	------	----------

Perlindungan	IP 67
--------------	-------

Data teknis

Material	TPU transparan
Material bodi detakan	TPU, transparan
Material mur	baja tahan karat (1.4404 / 316L)

Keterangan

Jumlah paket	1 buah
--------------	--------

E10593



Kabel koneksi dengan soket

ADOAH042VAS0025E03

Koneksi listrik


Kabel: 25 m, PVC, oranye, Ø 5 mm; 3 x 0.34 mm²

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU, transparan; Penguncian: baja tahan karat (1.4404 / 316L); Torsi pengencangan: 0.5 Nm



Koneksi

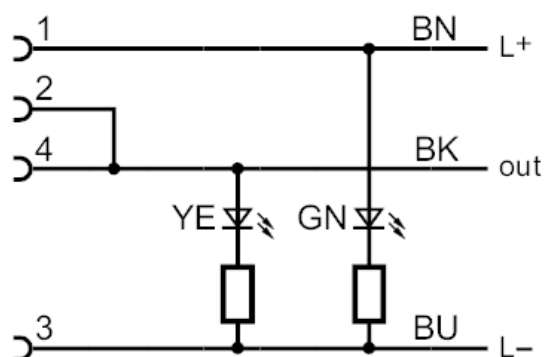

BK =
BN =
BU =

Warna core :
hitam
coklat
biru