


E10611



Kabel koneksi dengan soket

ADOAH042VAS0020E03

Produk tidak tersedia - entri arsip

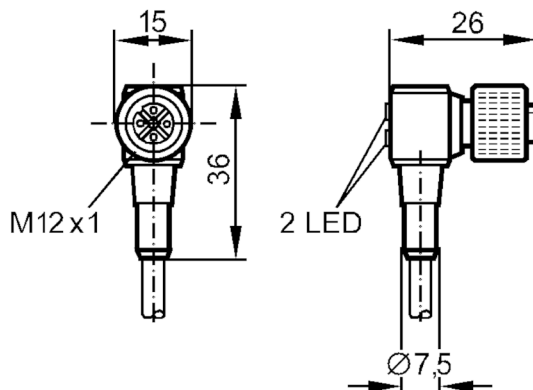

Data kelistrikan

Tegangan pengoperasian [V] 10...30 DC

Output

Desain kelistrikan PNP

Kondisi pengoperasian

Suhu sekitar [°C] -25...90

Perlindungan IP 67

Data teknis

Material PUR

Material bodi detakan PUR

Material mur baja tahan karat (1.4305/303)

Keterangan

 
Jumlah paket 1 buah

Koneksi listrik

Kabel: 20 m, PVC, hitam, Ø 4.5 mm; 3 x 0.34 mm²

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: baja tahan karat (1.4305/303)




E10611



Kabel koneksi dengan soket

ADOAH042VAS0020E03

Koneksi

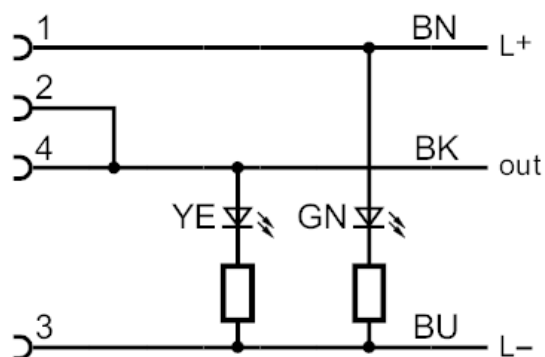

BK =
BN =
BU =

Warna core :
hitam
coklat
biru