


E10617



Kabel koneksi

VDOAF032ZDS00,6A03STGH030ZDS

Produk tidak tersedia - entri arsip

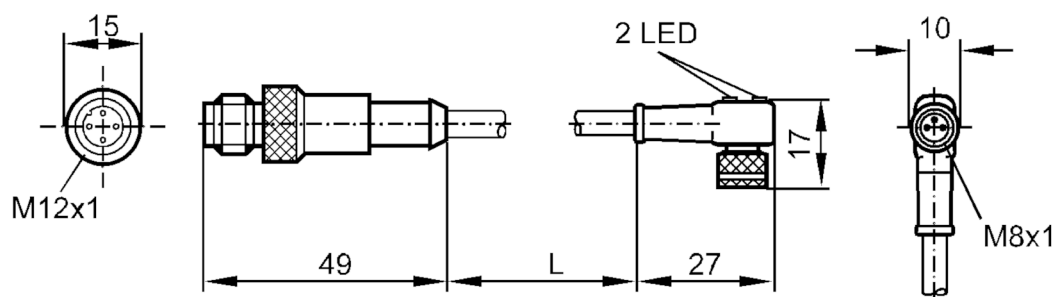

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
Kelas perlindungan		III

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 68

Data teknis

Dimensi	[mm]	15 x 15 x 46
Material		PUR
Material bodi detakan		PUR
Material mur		seng tuang, berlapis nikel

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

Kabel koneksi

VDOAF032ZDS00,6A03STGH030ZDS

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang, berlapis nikel



Koneksi listrik

Kabel: 0.6 m, PUR / PVC; 3 x 0.34 mm² (182 x Ø 0.05 mm)


Koneksi



Koneksi listrik - Buchse



Koneksi

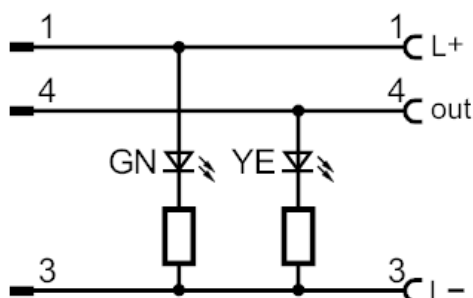

E10617



Kabel koneksi

VDOAF032ZDS00,6A03STGH030ZDS

Koneksi listrik - soket

Konektor: 1 x M8, bersiku; Bodi cetakan: PUR; Penguncian: seng tuang, berlapis nikel