




Kabel koneksi

VDOAH042ZDS00,3A03STGH030ZDS

Produk tidak tersedia - entri arsip

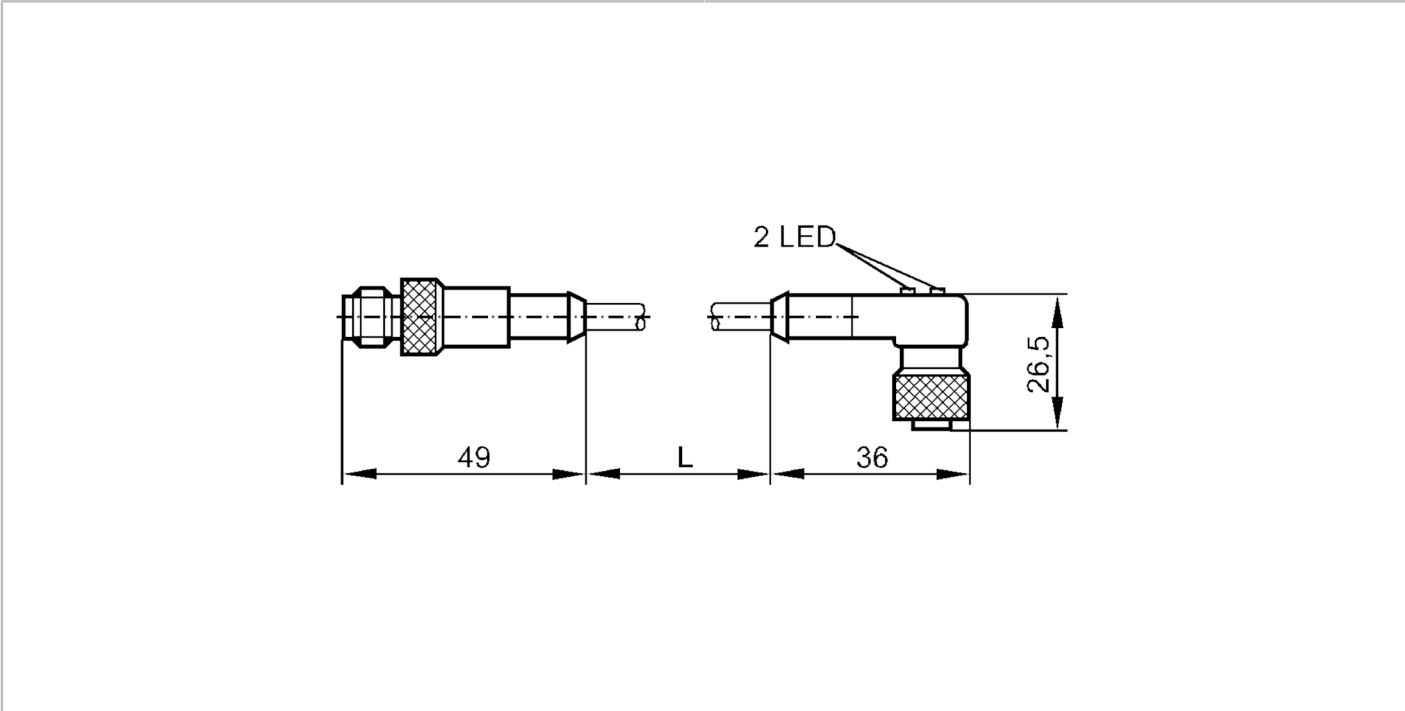

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 68

Data teknis

Material	PUR
Material bodi detakan	PUR
Material mur	seng tuang, berlapis nikel

Elemen display/pengoperasian


Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang, berlapis nikel

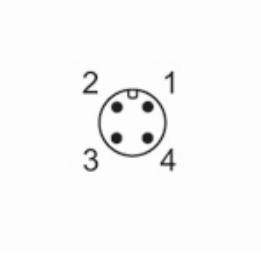

E10628



Kabel koneksi

VDOAH042ZDS00,3A03STGH030ZDS

Koneksi listrik

Kabel: 0.3 m, PUR / PVC; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Koneksi



Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang, berlapis nikel

