


E10631



Kabel koneksi

VDOAH040ALS0002E03STGH040ALS

Produk tidak tersedia - entri arsip

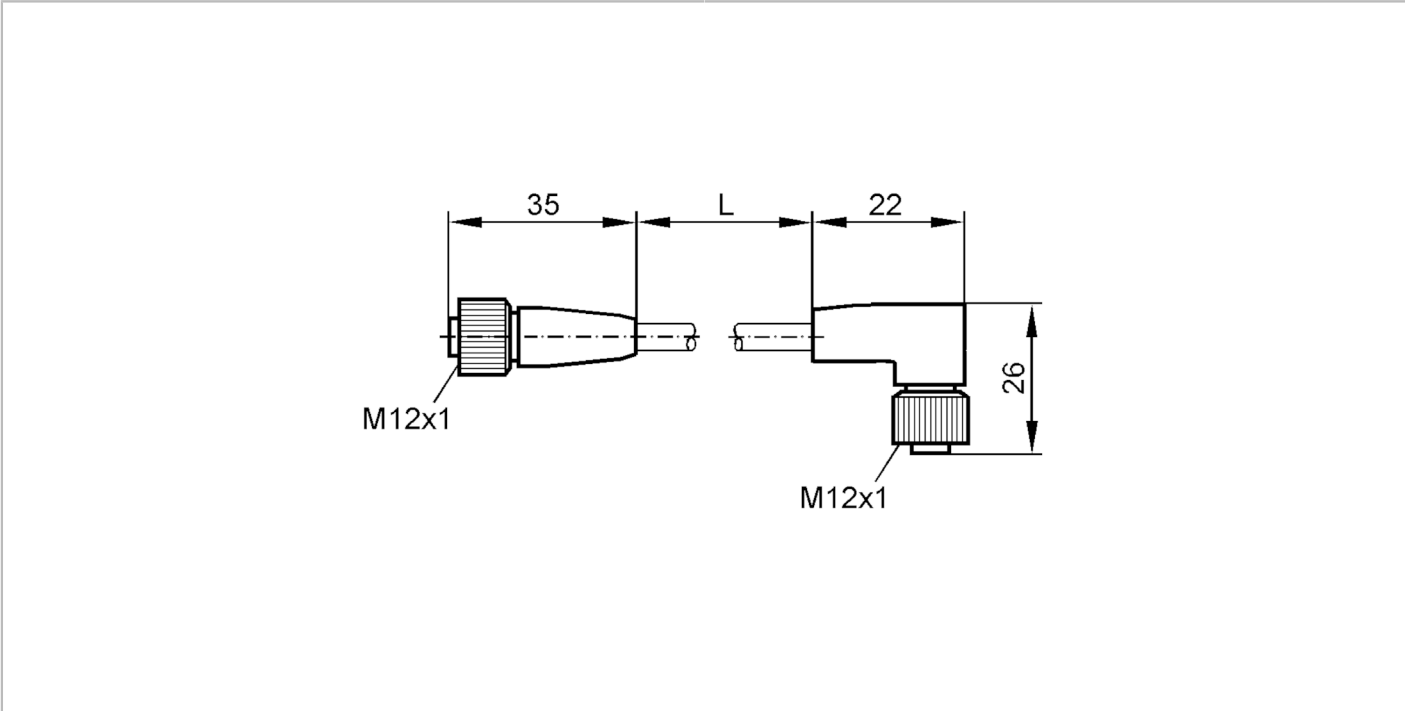

Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...70
Perlindungan		IP 67
Data teknis		
Material		PA 6.6
Material bodi detakan		PA 6.6
Material mur		seng tuang, berlapis nikel
Keterangan		
Jumlah paket		1 buah

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PA 6.6; Penguncian: seng tuang, berlapis nikel



E10631




Kabel koneksi

VDOAH040ALS0002E03STGH040ALS

Koneksi listrik

Kabel: 2 m, PUR / PVC; 3 x 0.34 mm²

Koneksi

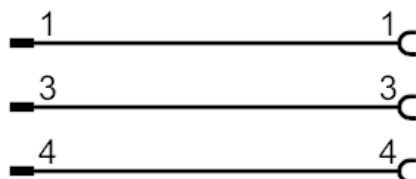

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PA 6.6; Penguncian: seng tuang, berlapis nikel

