


# E10656



## Kabel koneksi

VDOAH042MSS01,5A03STGH030MSS

Produk tidak tersedia - entri arsip

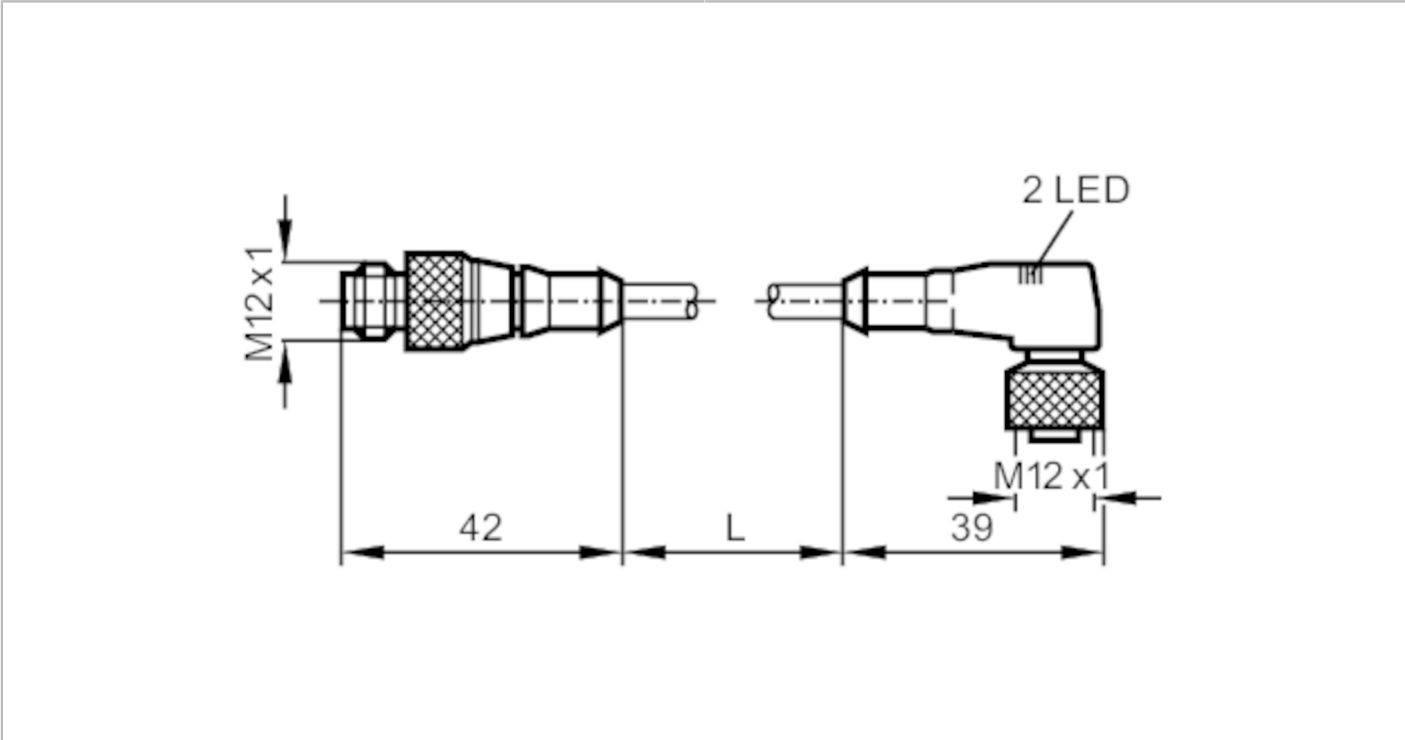

| Data kelistrikan             |                  |                          |
|------------------------------|------------------|--------------------------|
| Tegangan pengoperasian       | [V]              | 10...30 DC               |
| Kondisi pengoperasian        |                  |                          |
| Suhu sekitar                 | [°C]             | -25...90                 |
| Perlindungan                 |                  | IP 67                    |
| Data teknis                  |                  |                          |
| Material                     |                  | PUR                      |
| Material bodi detakan        |                  | PUR                      |
| Material mur                 |                  | kuningan, berlapis nikel |
| Elemen display/pengoperasian |                  |                          |
| Display                      | status peralihan | 1 x LED, kuning          |
|                              | operasi          | 1 x LED, hijau           |
| Keterangan                   |                  |                          |
| Jumlah paket                 |                  | 1 buah                   |
| Koneksi listrik - colokan    |                  |                          |

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm



# E10656




## Kabel koneksi

VDOAH042MSS01,5A03STGH030MSS

### Koneksi listrik

Kabel: 1.5 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Koneksi

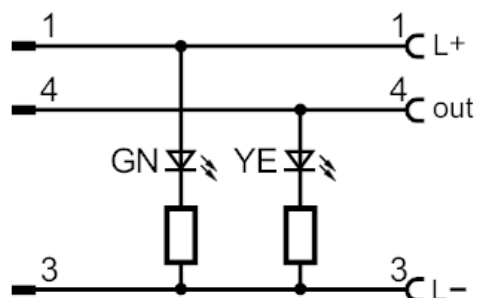

### Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

