


Kabel koneksi

VDOAF032MSS01,5A03STGH030MSS

Produk tidak tersedia - entri arsip

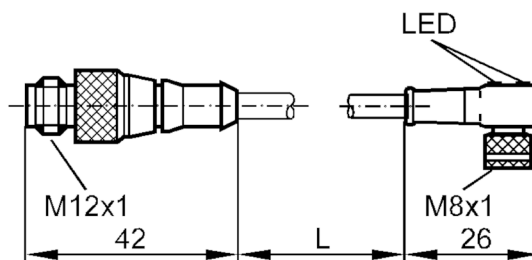

Data kelistrikan

Tegangan pengoperasian [V] 10...30 DC

Kelas perlindungan III

Output

Desain kelistrikan PNP

Kondisi pengoperasian

Suhu sekitar [°C] -25...90

Perlindungan IP 67

Data teknis

Material PUR

Material bodi detakan PUR

Material mur kuningan, berlapis nikel

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket 1 buah

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel



E10658




Kabel koneksi

VDOAF032MSS01,5A03STGH030MSS

Koneksi listrik

Kabel: 1.5 m, PUR / PVC; 3 x 0.34 mm² (42 x Ø 0.1 mm)


Koneksi

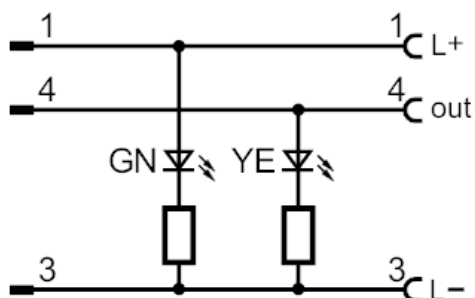

Koneksi listrik - Buchse



Koneksi

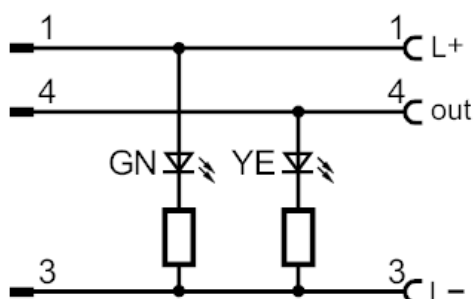

Koneksi listrik - soket

Konektor: 1 x M8, bersiku; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel