


# E10660



## Kabel koneksi dengan soket

ADOGK190MSS0005B19


Produk tidak tersedia - entri arsip

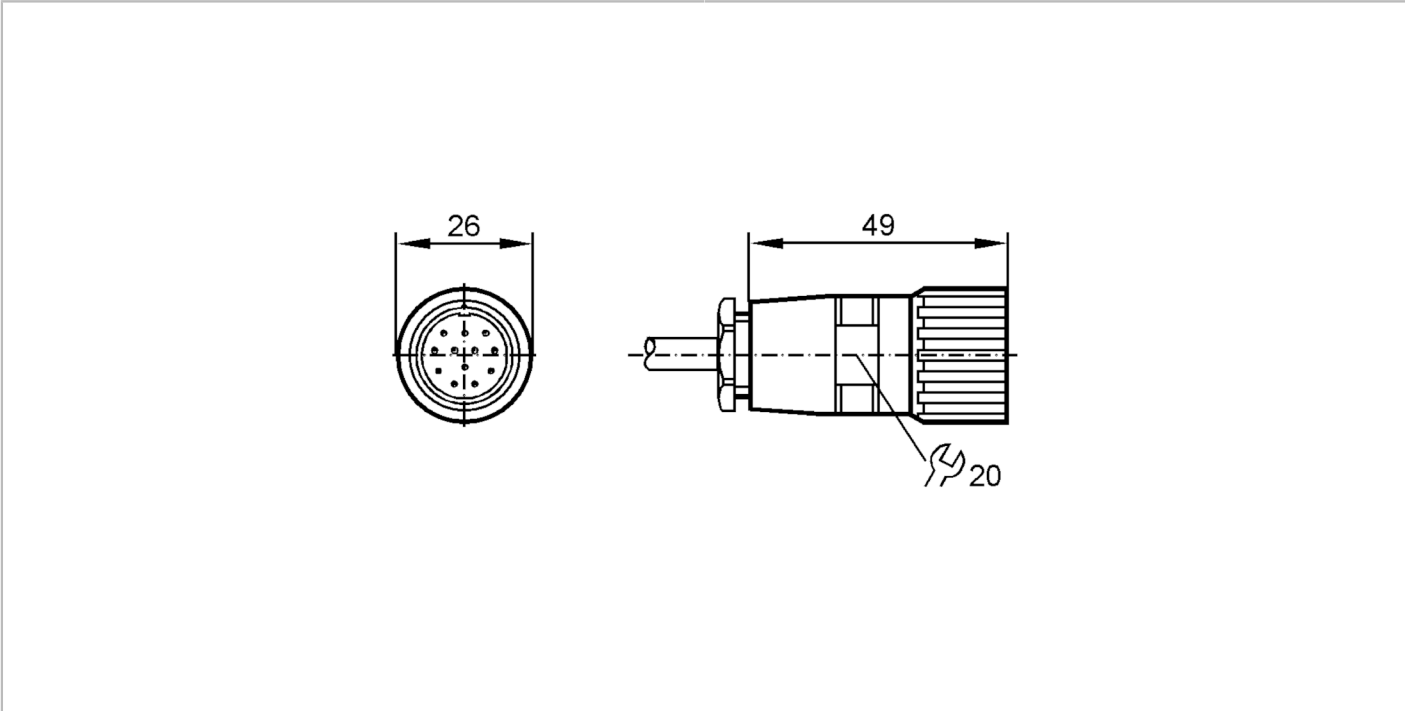

| Data kelistrikan       |      |                          |
|------------------------|------|--------------------------|
| Tegangan pengoperasian | [V]  | 10...30 DC               |
| Kondisi pengoperasian  |      |                          |
| Perlindungan           |      | IP 65                    |
| Data teknis            |      |                          |
| Dimensi                | [mm] | 26 x 26 x 49             |
| Material               |      | kuningan berlapis nikel  |
| Material bodi detakan  |      | kuningan, berlapis nikel |
| Material mur           |      | kuningan, berlapis nikel |
| Keterangan             |      |                          |
| Jumlah paket           |      | 1 buah                   |

| Koneksi listrik                                            |  |
|------------------------------------------------------------|--|
| Kabel: 5 m, PUR; 16 x 0.5 mm <sup>2</sup> (64 x Ø 0.1 mm ) |  |

| Koneksi listrik - soket                                                                         |  |
|-------------------------------------------------------------------------------------------------|--|
| Konektor: 1 x M23; Bodi cetakan: kuningan, berlapis nikel; Penguncian: kuningan, berlapis nikel |  |

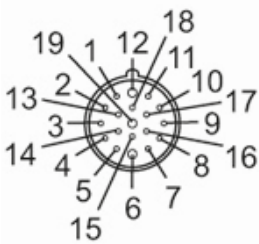



## Kabel koneksi dengan soket

ADOGK190MSS0005B19

## Koneksi

|    |       |
|----|-------|
| 1  | VT    |
| 2  | RD    |
| 3  | GY    |
| 4  | RD/BU |
| 5  | GN    |
| 6  | BU    |
| 7  | GY/PK |
| 8  | WH/GN |
| 9  | WH/YE |
| 10 | WH/GY |
| 11 | BK    |
| 12 | GN/YE |
| 13 | YE/BN |
| 14 | BN/GN |
| 15 | WH    |
| 16 | YE    |
| 17 | PK    |
| 18 | GY/BN |
| 19 | BN    |

|      |              |
|------|--------------|
|      | Warna core : |
| BK = | hitam        |
| BN = | coklat       |
| BU = | biru         |
| GN = | hijau        |
| GY = | abu-abu      |
| PK = | merah muda   |
| RD = | merah        |
| VT = | ungu         |
| WH = | putih        |
| YE = | kuning       |