


E10666



Kabel koneksi

VDOAH042MSS00,3A03STGH030MSS

Produk tidak tersedia - entri arsip

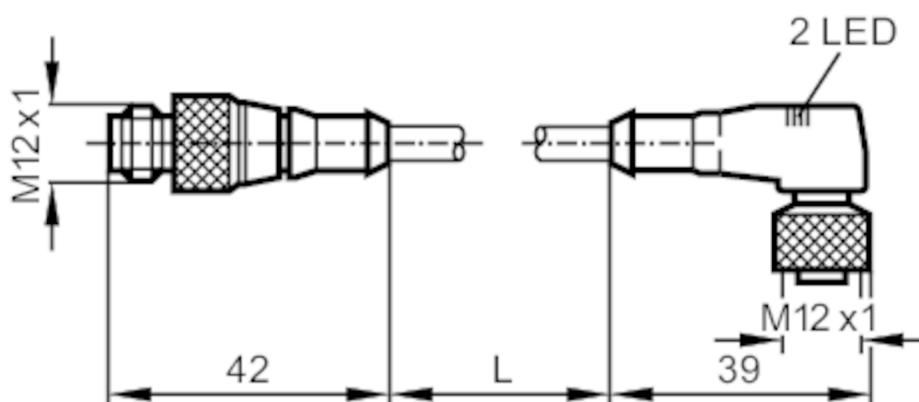

Data kelistrikan

Tegangan pengoperasian [V] 10...30 DC

Output

Desain kelistrikan PNP

Kondisi pengoperasian

Suhu sekitar [°C] -25...90

Perlindungan IP 67

Data teknis

Material PUR

Material bodi detakan PUR

Material mur kuningan, berlapis nikel

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket 1 buah

Kabel koneksi

VDOAH042MSS00,3A03STGH030MSS

Koneksi listrik - colokan


Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm



Koneksi listrik

Kabel: 0.3 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi

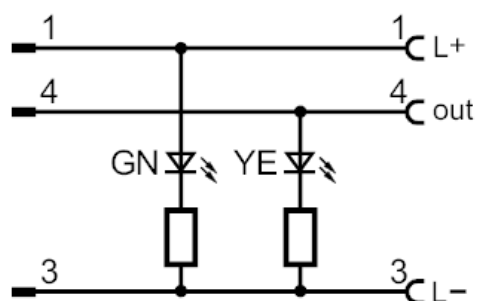

Warna core :
 BK = hitam
 BN = coklat
 BU = biru

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

