

E10667



Kabel jumper dengan soket katup


VVSAC041MSS0003B03STGH030MSS

Produk tidak tersedia - entri arsip

1 abu-abu

Data kelistrikan		
Tegangan pengoperasian	[V]	< 24 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 65
Data teknis		
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
Keterangan		
Jumlah paket		1 buah
Koneksi listrik - colokan		

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

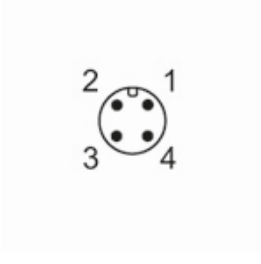


Kabel jumper dengan soket katup

VVSAC041MSS0003B03STGH030MSS

Koneksi listrik

Kabel: 3 m, PUR; 3 x 0.34 mm²

Koneksi

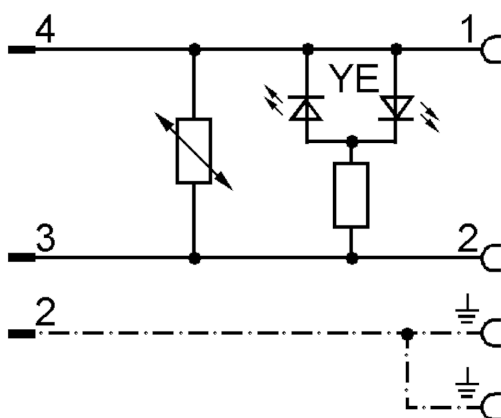

Koneksi listrik - soket

Konektor: 1 x katup tipe A DIN, bersiku; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

