


E10781



Kabel koneksi

VDOAH040ZDS0010A03STGH040ZDS

Produk tidak tersedia - entri arsip

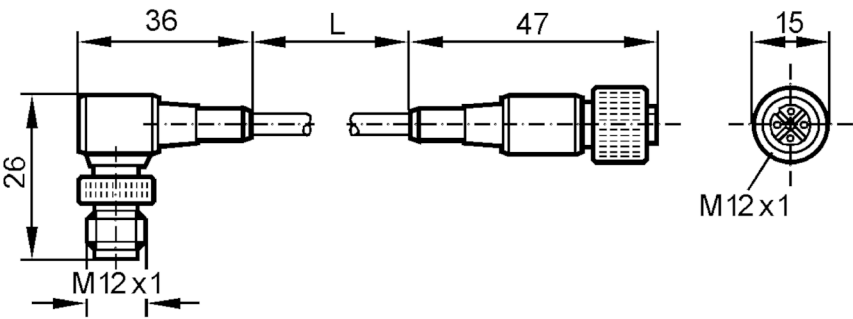

Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 68
Data teknis		
Material		PUR
Material bodi detakan		PUR
Material mur		ZnAl / Ni
Keterangan		
Jumlah paket		1 buah

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: ZnAl / Ni



E10781



Kabel koneksi

VDOAH040ZDS0010A03STGH040ZDS

Koneksi listrik

Kabel: 10 m, PUR / PVC, hitam; 4 x 0.34 mm² (182 x Ø 0.05 mm)

Koneksi



Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: ZnAl / Ni

