




Kabel koneksi dengan soket

ADOGH040ZDS0015A03

Produk tidak tersedia - entri arsip

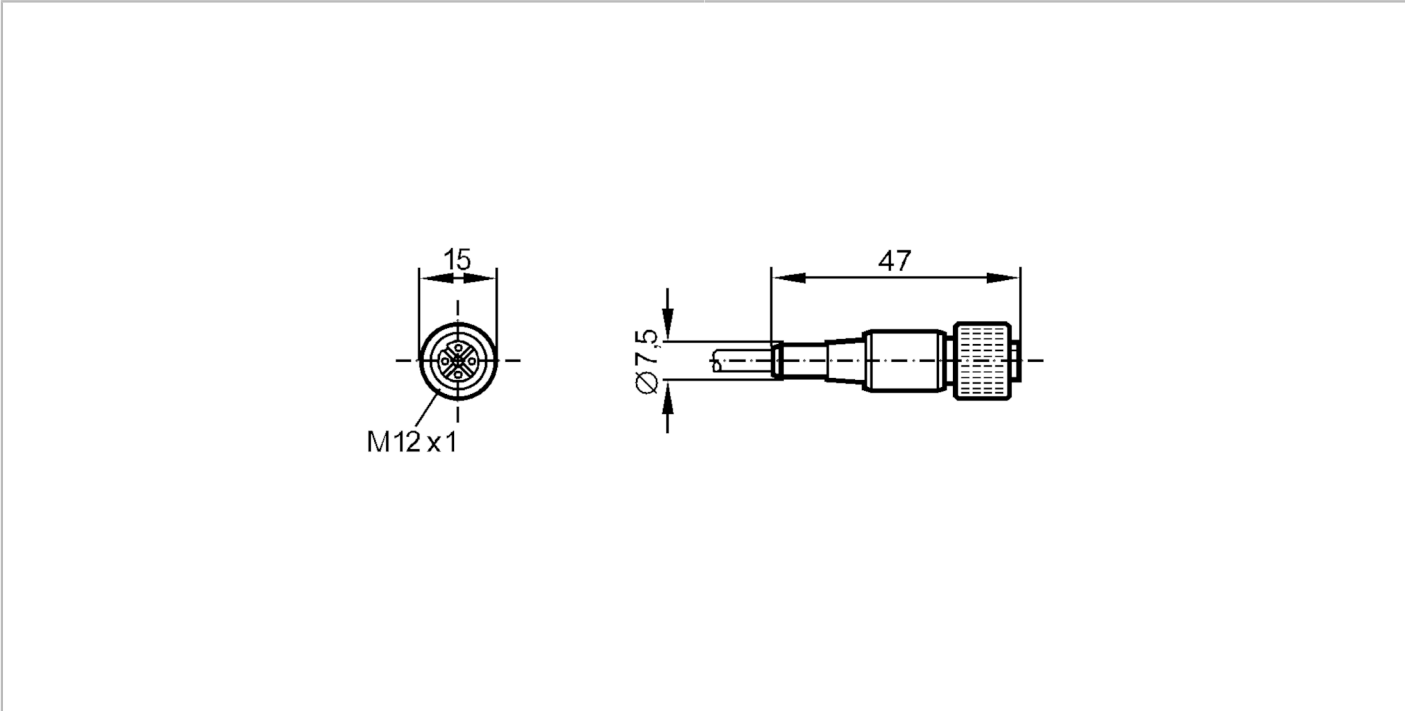

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC/DC
------------------------	-----	-------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Dimensi	[mm]	15 x 15 x 47
Material		PUR
Material bodi detakan		PUR
Material mur		seng tuang, berlapis nikel

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 15 m, PUR / PVC, hitam, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)
--

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang, berlapis nikel
--

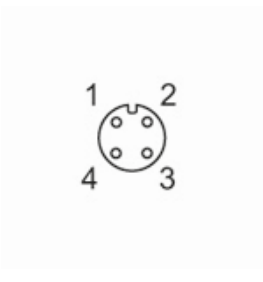


E10783



Kabel koneksi dengan soket

ADOGH040ZDS0015A03

Koneksi

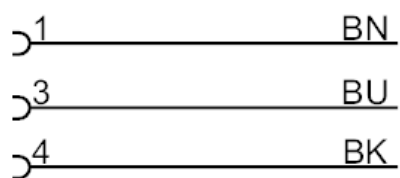

BN =	Warna core :	coklat
BK =		hitam
BU =		biru