


Kabel koneksi dengan soket

ADOAH040MSS0015A04

Produk tidak tersedia - entri arsip

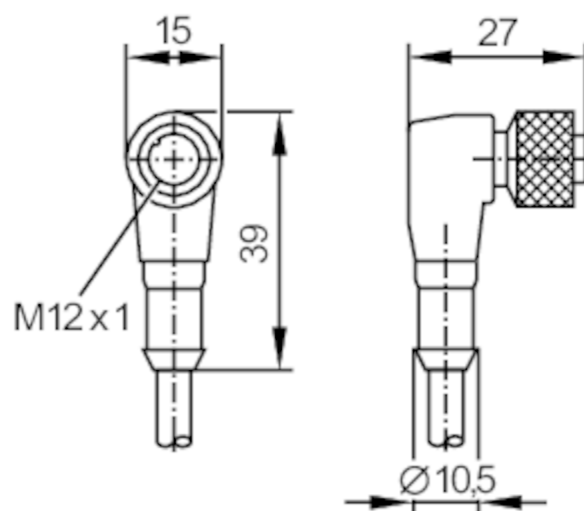

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC / < 300 DC
------------------------	-----	---------------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Dimensi	[mm]	27 x 15 x 39
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel

Keterangan


Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik

Kabel: 15 m, PUR / PVC, oranye, Ø 5 mm; 4 x 0.25 mm²

Koneksi listrik - soket

 Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm




E10784



Kabel koneksi dengan soket

ADOAH040MSS0015A04

Koneksi

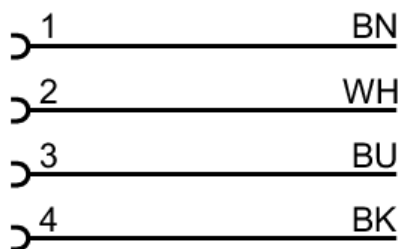

BN =	Warna core :	coklat
BK =		hitam
BU =		biru
WH =		putih