


E10786



Kabel koneksi dengan soket

ADOGF030MSS0005E03

Produk tidak tersedia - entri arsip

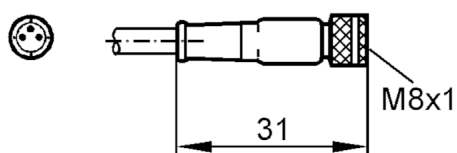

Data kelistrikan

Tegangan pengoperasian	[V]	< 60 AC / < 75 DC
Kelas perlindungan		III

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Material	TPU
Material bodi detakan	TPU
Material mur	kuningan, berlapis nikel

Keterangan

Jumlah paket	1 buah
--------------	--------


**Kabel koneksi dengan soket**

ADOGF030MSS0005E03

Koneksi listrikKabel: 5 m, PVC, oranye, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)**Koneksi listrik - soket**

Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

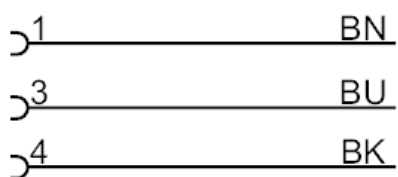**Koneksi**

BK = Warna core :
BN = hitam
BU = coklat
 biru