


E10787



Kabel koneksi dengan soket

ADOAF030MSS0005E03

Produk tidak tersedia - entri arsip

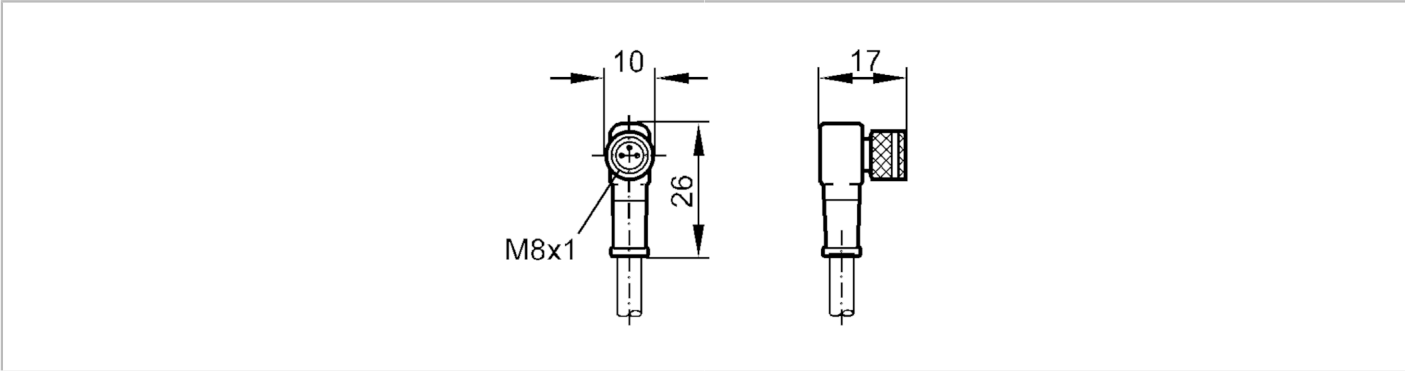

Data kelistrikan

Tegangan pengoperasian [V]	< 60 AC / < 75 DC
Kelas perlindungan	III

Kondisi pengoperasian

Suhu sekitar [°C]	-25...90
Perlindungan	IP 67

Data teknis

Material	TPU
Material bodi detakan	TPU
Material mur	kuningan, berlapis nikel

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 5 m, PVC, oranye, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Koneksi listrik - soket

Konektor: 1 x M8, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

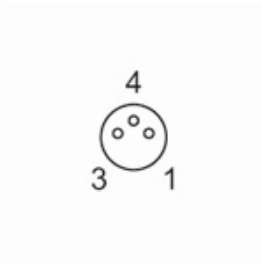


E10787



Kabel koneksi dengan soket

ADOAF030MSS0005E03

Koneksi

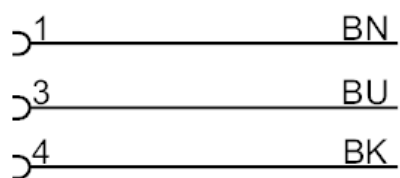

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru