




Colokan berkabel

SSTAA030MSSFKPG

Produk tidak tersedia - entri arsip

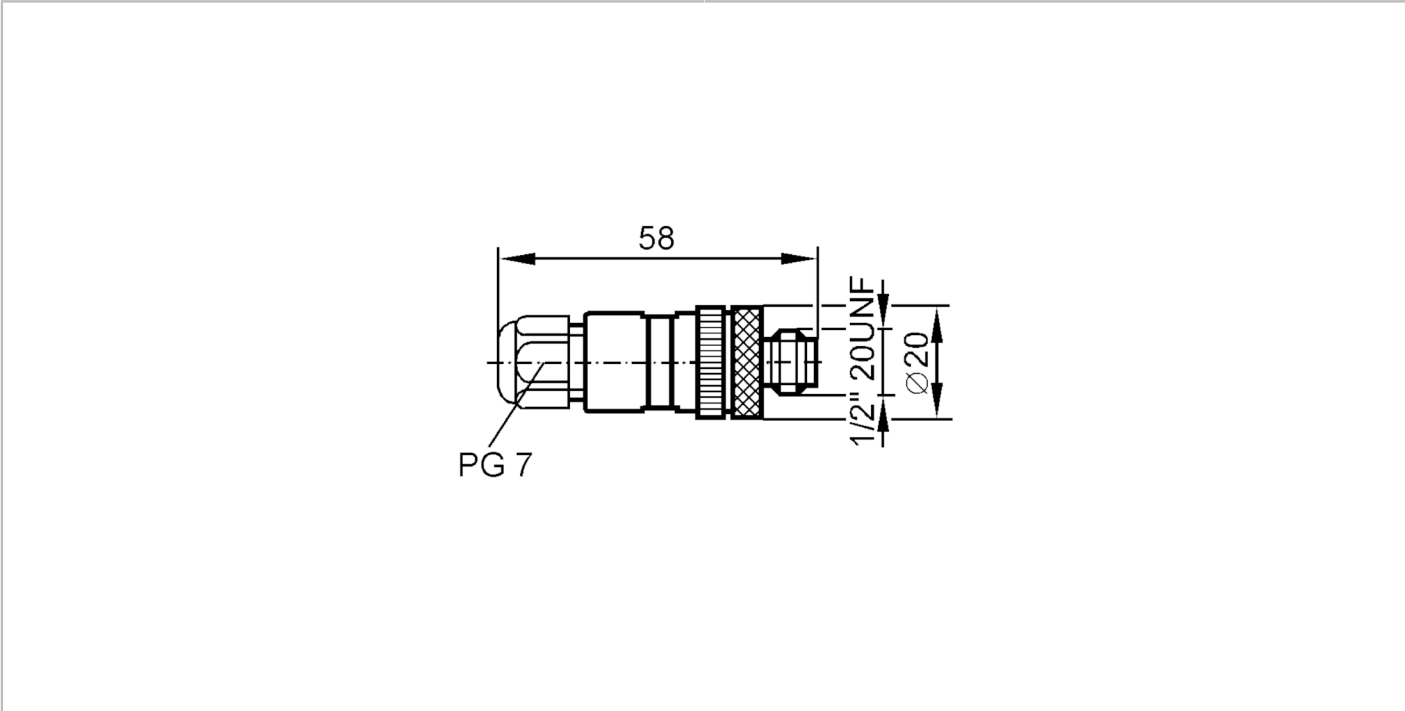

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC
------------------------	-----	----------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Berat	[g]	25
Dimensi	[mm]	20 x 20 x 58
Material		PA
Material bodi detakan		PA
Material mur		kuningan, berlapis nikel

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

terminal: ...0.75 mm²; Konektor kabel: PG 7

Koneksi listrik - colokan

Konektor: 1 x 1/2", lurus; pengkodean: C; Bodi cetakan: PA; Penguncian: kuningan, berlapis nikel

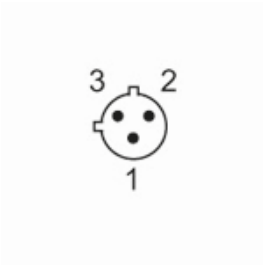

E10788



Colokan berkabel

SSTAA030MSSFKPG

Koneksi

