




Soket berkabel

SDOGA030MSSFKPG

Produk tidak tersedia - entri arsip

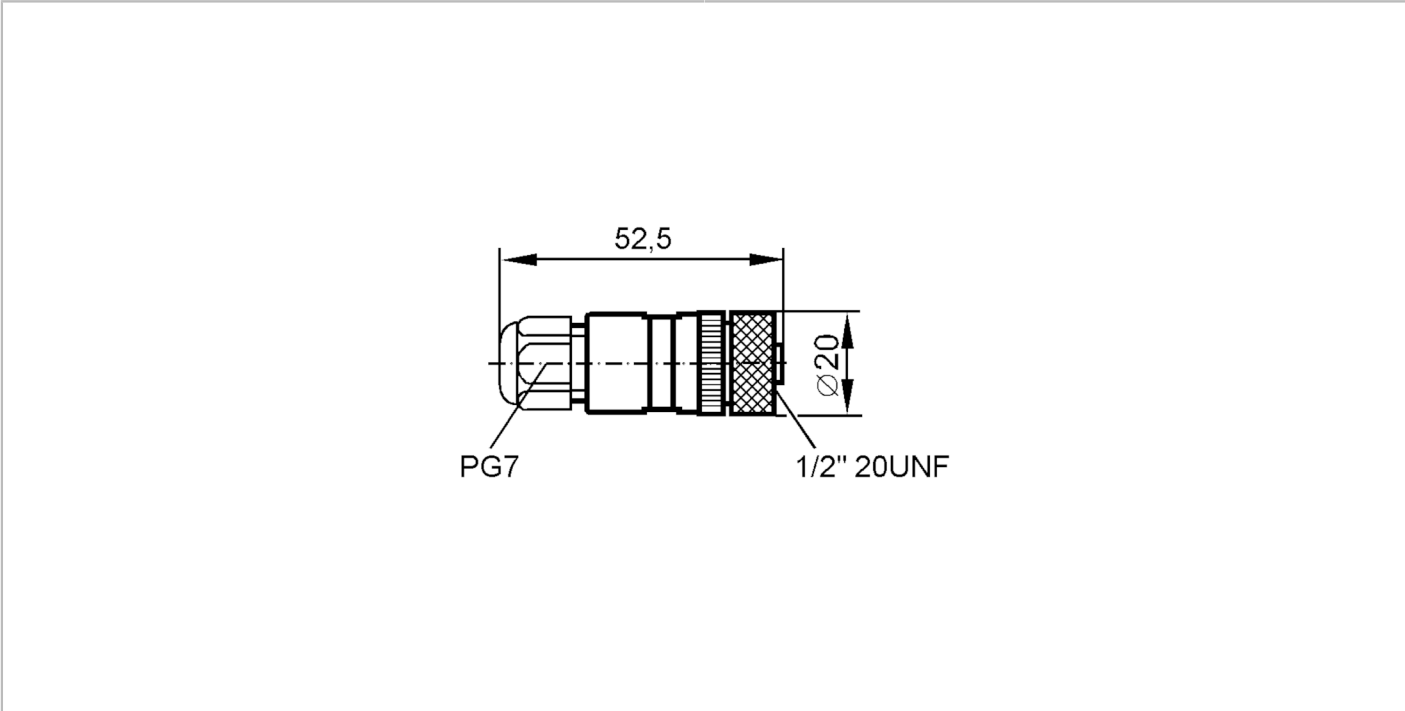

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC
------------------------	-----	----------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Berat	[g]	25
Dimensi	[mm]	20 x 20 x 52.5
Material		PA
Material bodi detakan		PA
Material mur		kuningan, berlapis nikel

Keterangan


Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik

terminal: ...0.75 mm²

Koneksi listrik - soket

Konektor: 1 x 1/2", lurus; pengkodean: C; Bodi cetakan: PA; Penguncian: kuningan, berlapis nikel

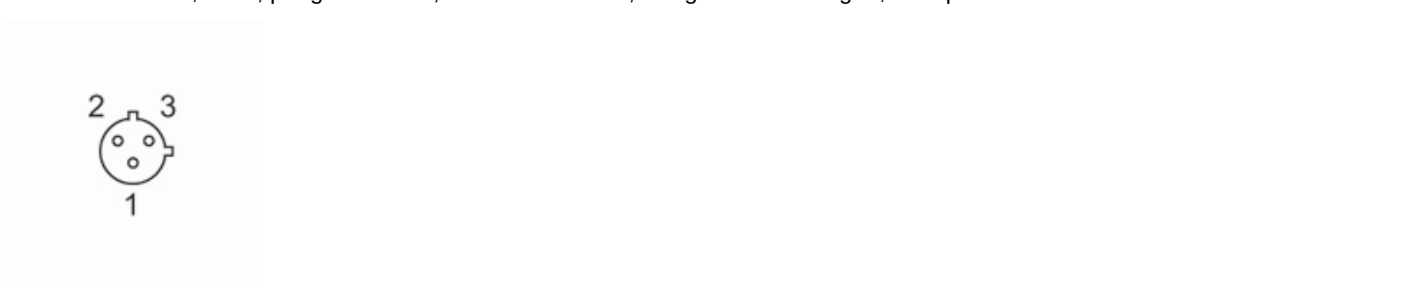

E10789

Soket berkabel

SDOGA030MSSFKPG



Koneksi

