


E10790



Soket berkabel

SDOAH040MSSFKPG

Produk tidak tersedia - entri arsip

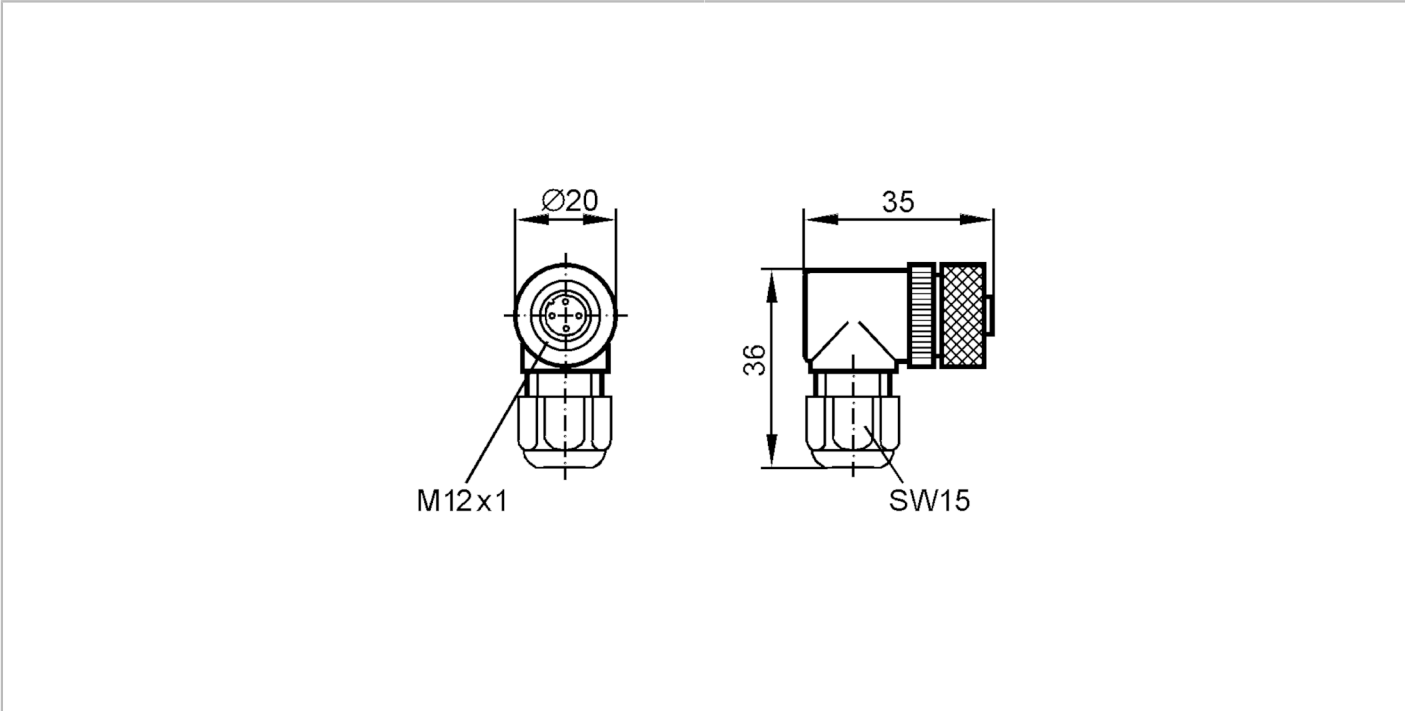

Data kelistrikan

Tegangan pengoperasian	[V]	< 125 AC / < 150 DC
------------------------	-----	---------------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Dimensi	[mm]	36 x 20 x 35
Material		PA
Material bodi detakan		PA
Material mur		kuningan, berlapis nikel

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik

terminal: ...0.75 mm²; Konektor kabel: PG 7

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PA; Penguncian: kuningan, berlapis nikel



E10790

Soket berkabel

SDOAH040MSSFKPG



Koneksi

