


E10802



Splitter Y

ZDO2F030MSS0000-00STGH040MSS

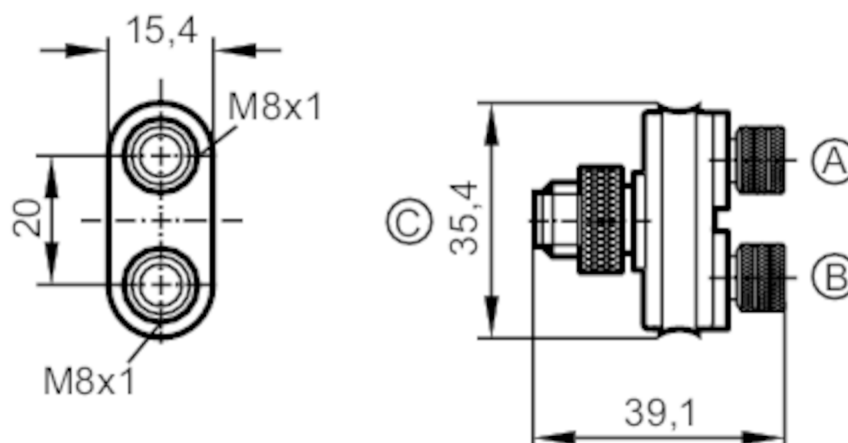

Aplikasi

Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian [V]	< 60 DC
Kelas perlindungan	III
Beban arus maks. per modul/slot [A]	3
Total beban arus maks. [A]	3

Kondisi pengoperasian

Suhu sekitar [°C]	-25...90
Perlindungan	IP 67

Data teknis

Berat [g]	21.8
Dimensi [mm]	15.4 x 35.4 x 39.1
Material	PUR
Material bodi detakan	PUR
Material mur	kuningan, berlapis nikel
Tipe konektor	M8

Keterangan

Jumlah paket	1 buah
--------------	--------

E10802



Splitter Y

ZDO2F030MSS0000-00STGH040MSS


Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas



Koneksi listrik

Koneksi

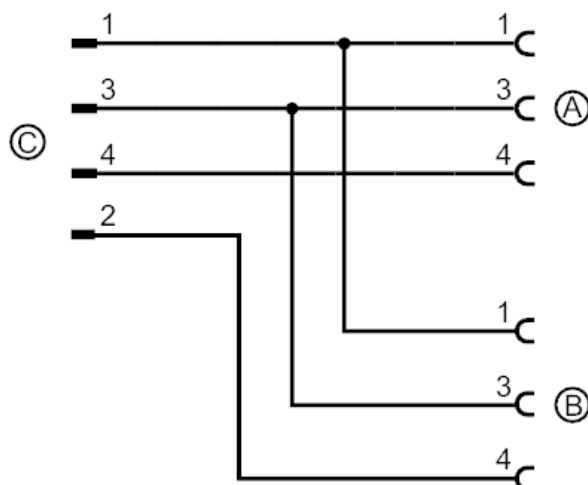

Koneksi listrik - soket

Konektor: 2 x M8; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

