


E10816



Kabel koneksi

VDOAH040MSS00,2A03STGX030

Produk tidak tersedia - entri arsip

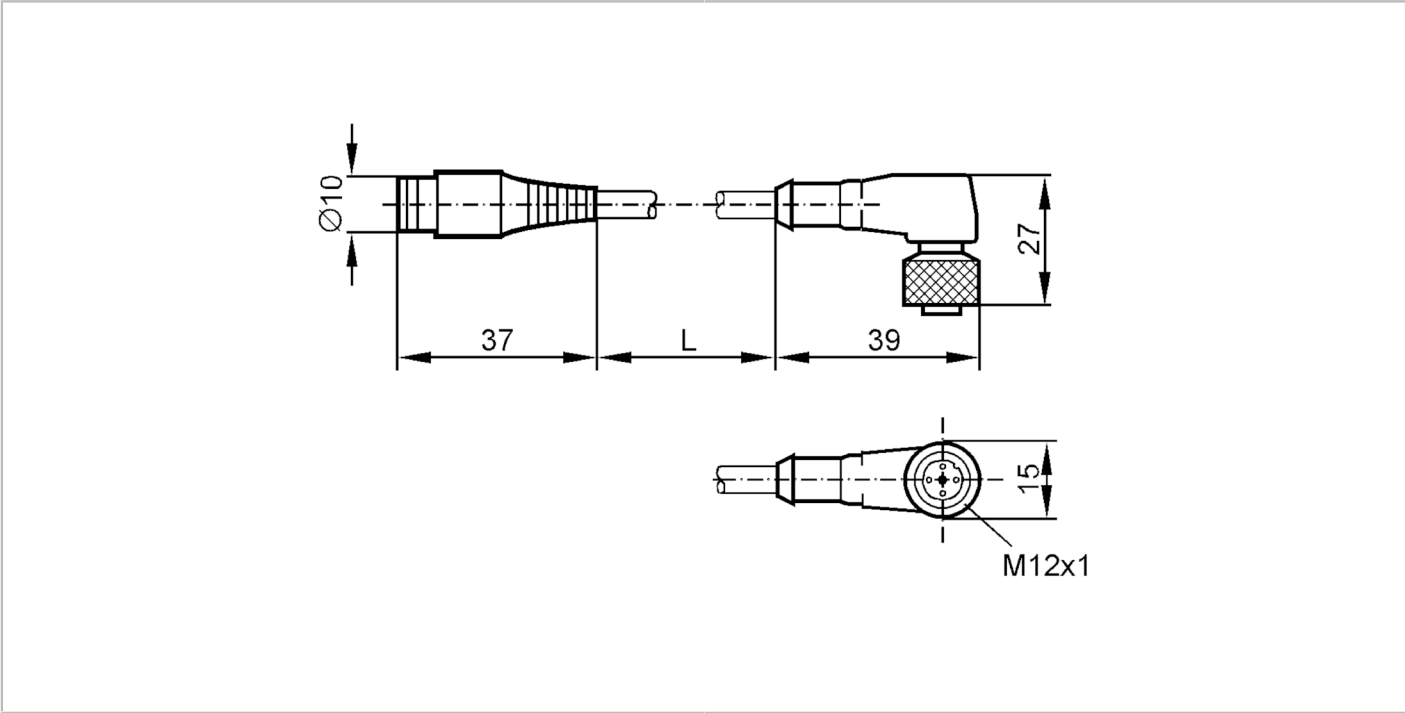

Data kelistrikan		
Tegangan pengoperasian	[V]	10...55 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...70
Perlindungan		IP 65
Data teknis		
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah

Koneksi listrik - colokan

Konektor: 1 x Torson, lurus; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel






Kabel koneksi

VDOAH040MSS00,2A03STGX030

Koneksi listrik

Kabel: 0.2 m, PUR / PVC

Koneksi

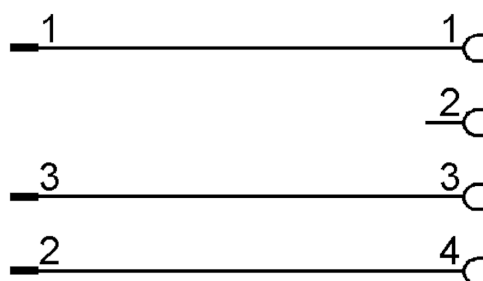

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

