


E10820



Kabel jumper dengan soket katup

VVSAB041--S00,6A03STAH030VAS

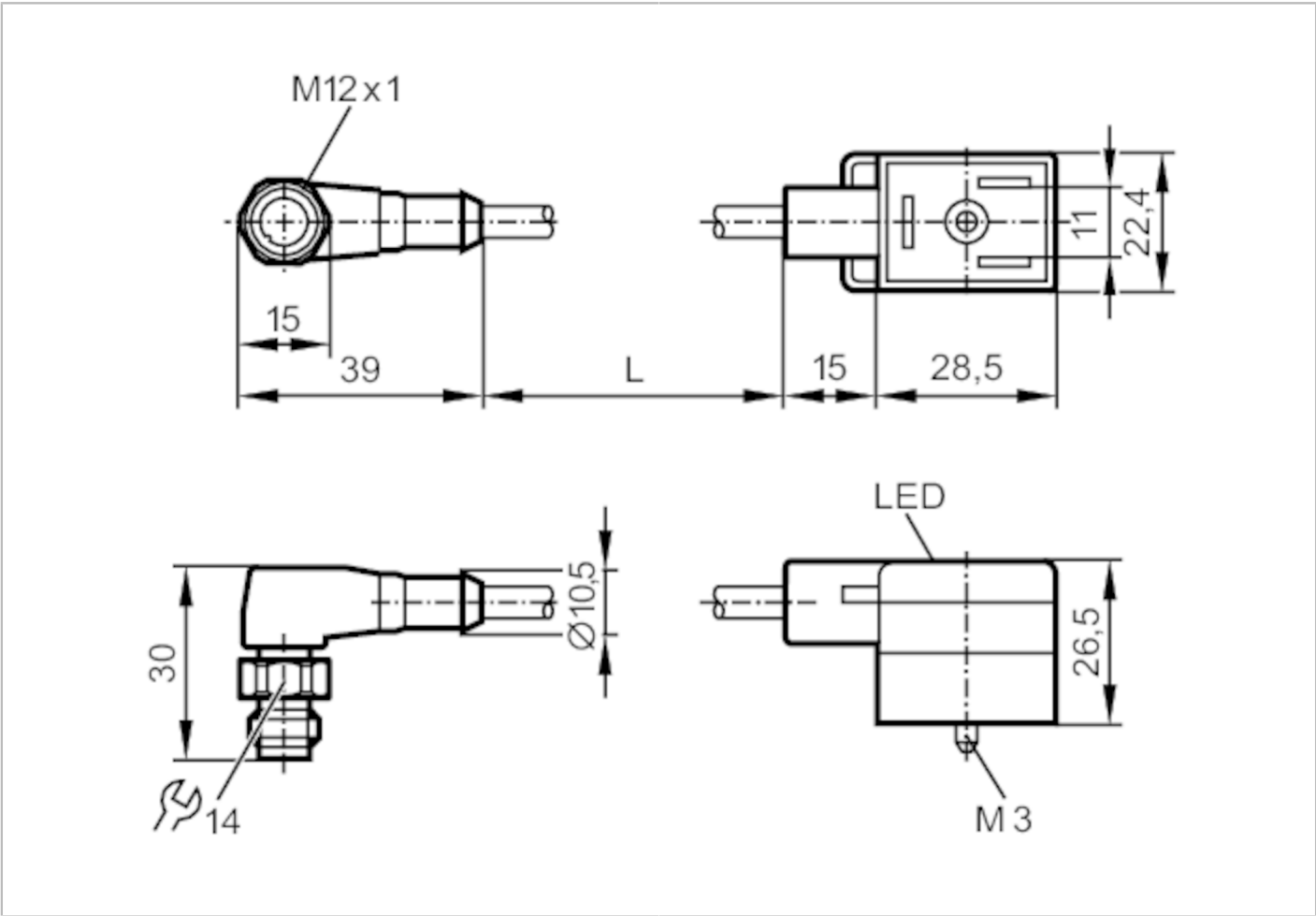

Aplikasi

Fitur khusus

Bebas halogen

Data kelistrikan

Tegangan pengoperasian

[V]

< 24 AC/DC

Pelindung tegangan berlebih

ya; (VDR)

Kondisi pengoperasian

Suhu sekitar

[°C]

-25...90

Perlindungan

IP 67

Data teknis

Berat

[g]

73.7

Dimensi

[mm]

30 x 15 x 39

Material

TPU

Material bodi detakan

TPU

Material mur

baja tahan karat (1.4404 / 316L)

Elemen display/pengoperasian

Display

operasi

1 x LED, kuning



Kabel jumper dengan soket katup

VVSAB041--S00,6A03STAH030VAS

Aksesori

Item dikirim

sekrup

panel untuk pelabelan

 
Keterangan

Jumlah paket

1 buah

Koneksi listrik - colokan


Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: baja tahan karat (1.4404 / 316L)



Koneksi listrik

Kabel: 0.6 m, PUR, Bebas halogen, hitam, Ø 4.8 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Koneksi

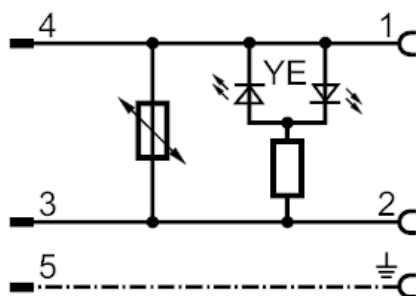

Koneksi listrik - soket

Konektor: 1 x katup tipe B standar industri, bersiku; Bodi cetakan: TPU; Penguncian: baja tahan karat (1.4404 / 316L)

