


E10865



Kabel koneksi dengan soket

ADOAH030MSS0002E03

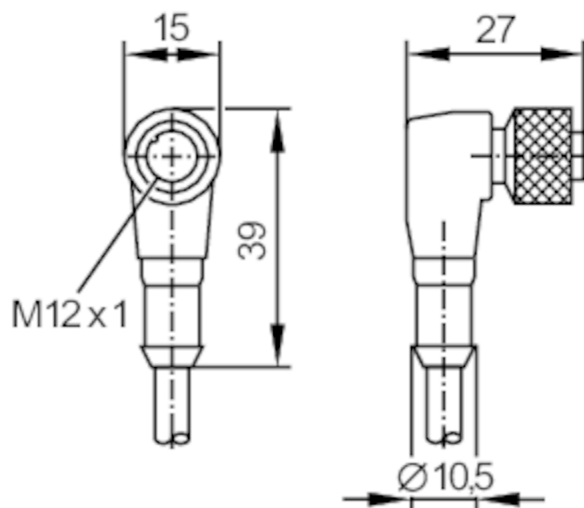

Data kelistrikan

Tegangan pengoperasian [V] < 250 AC / < 300 DC

Kondisi pengoperasian

Suhu sekitar [°C] -25...90

Perlindungan IP 67

Data teknis

Berat [g] 90.1

Dimensi [mm] 27 x 15 x 39

Material TPU

Material bodi detakan TPU

Material mur kuningan, berlapis nikel

Keterangan

Jumlah paket 1 buah

E10865



Kabel koneksi dengan soket

ADOAH030MSS0002E03

Koneksi listrik


Kabel: 2 m, PVC, oranye, Ø 5 mm; 3 x 0.34 mm² (19 x Ø 0.16 mm) / AWG 22

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: C; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm



Koneksi

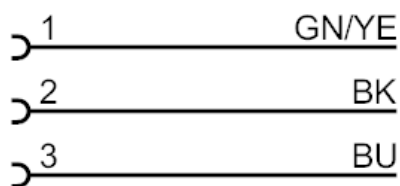

BK =	Warna core :
BU =	hitam
GN/YE =	biru
	hijau/kuning